


UNC #4-40 Hexscrew UNC #4-40 Hexnut

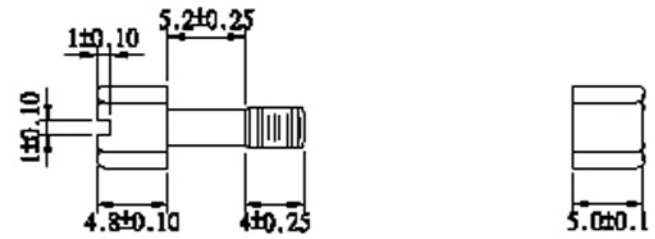

F/F GENDER CHANGER
PIN OUT: 15Female

		15Female
1	-----	1
2	-----	2
)	
14	-----	14
15	-----	15
G	-----	G

Label: yellow color with black character
 One side: MINI GENDER CHANGER
 The other side: U.S.A. PATENT 5199906 SEAL
SPECIFICATION
 INSULATOR: PBT Glass fibre reinforced UL 94 V0
 CONTACT: Brass
 CONTACT PLATING: Gold plated over nickel
 SHELL: Tin Plated Shell
 CURRENT RATING: 3 AMP
 DIELECTRIC STRENGTH: 1000V AC for one minute
 INSULATOR RESISTANCE: 1000MΩ min at 500V DC
 TEMPERATURE: -55°C +105°C

TITLE		SCALE
RS232 GENDER CHANGER		NTS
DRAWING NO.	32-026	
		UNITS mm
FILE NAME	32-026.pdf	SHEET 1/1



Mode Electronics Part Number 32-026-0