
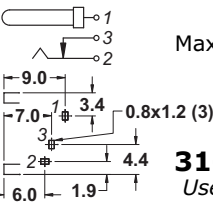


Max. 2A @ 16VDC  
**31-157-0** 2.1mm  
**31-158-0** 2.5mm  
 Use -1 for Display Pkg.

Max. 2A @ 16VDC  
**31-159-0** 2.5mm  
 Use -2 for Display Pkg.

**TEST JACKS & PLUGS**

**CHASSIS BANANA JACKS**




**31-401-0** Black  
**31-400-2** Red and Black Pkg (2)  
**31-402-0** Red

**CHASSIS BANANA JACKS**




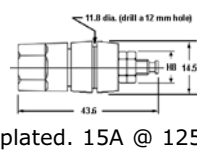

Multi-colored chassis mounting Banana jacks.  
**31-411-0** Black  
**31-414-0** Yellow  
**31-416-0** Blue  
**31-412-0** Red  
**31-415-0** Green  
**31-419-0** White  
**31-410-2** Red/Black  
**31-410-6** Asst. (6)

**BINDING POSTS**




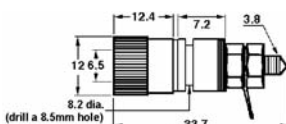

**31-421-0** Black  
**31-420-2** Pkg (red & blk)  
**31-422-0** Red  
**31-425-0** Green

**LARGE BINDING POSTS**

Gold plated. 15A @ 125V AC  
**31-441-0** Black  
**31-442-0** Red  
**31-443-2** Pkg (red & blk)

**LOW PROFILE BINDING POSTS**


 
**31-431-0** Black  
**31-430-2** Pkg 1 red 1 black  
**31-432-0** Red

**DUAL BINDING POSTS**




Gold plated  
**31-440-0** Bulk  
**31-440-1** Pkg


**BANANA PLUGS**

**31-461-0** Black  
**31-460-2** Pkg 1 red 1 black  
**31-462-0** Red

**COMPUTER ACCESSORIES**

**RS232 GENDER CHANGERS**




Low profile gender changers with appropriate mounting hardware.  
 Use -1 for Display Package (except 32-025-0)

Positions	male-male	male-female	fem-fem
9-pos.	<b>32-021-0</b>	<b>32-022-0</b>	<b>32-023-0</b>
15-pos.			<b>32-026-0</b>
25-pos.	<b>32-027-0</b>	<b>32-028-0</b>	<b>32-029-0</b>

**32-021HD-0** 15-pos., high density, male-male  
**32-023HD-0** 15-pos., high density, fem.-fem.

**MODULAR PHONE JACK TO RS232 ADAPTERS**



**Note:** RJ45(8C) types will accept RJ12(6C) plugs.  
 RJ12 = 6P/6C  
 RJ45 = 8P/8C

**32-321-0** RJ45(8C) - 9-position male  
**32-322-0** RJ45(8C) - 9-position female  
**32-323-0** RJ45(8C) - 15-position male  
**32-325-0** RJ45(8C) - 25-position male  
**32-326-0** RJ45(8C) - 25-position female  
 Use -1 for Display Package

**A-A USB2.0 CABLE**



**32-406-0** 6' long  
**32-410-0** 10' long  
**32-406-1** Pkg  
**32-410-1** Pkg



**60MHz SCOPE PROBE**

1.5 meter length  
Attenuation: 1x and 10x  
Input Resistance: 1 M and 10 M ohms  
Bandwidth: 6MHz(400V Peak to peak max.)  
60MHz(600V peak to peak max.)  
Compensation adjustment in BNC connector

**33-010-0** Bulk  
**33-010-1** Display Package



**100MHz SCOPE PROBE**

1.5 meter length  
Attenuation: 1x and 10x  
Input Resistance: 1 M and 10 M ohms  
Bandwidth: 10MHz (300V peak to peak max.)  
100MHz (600V peak to peak max.)  
Compensation adjustment in BNC connector  
Includes multi-accessory kit

**33-015-0** Bulk  
**33-015-1** Display Package

**METER REPLACEMENT LEAD**



Set of red & black test leads with banana plugs. Plugs & probes are molded.

**33-140-0** Set(bulk)  
**33-140-2** Package


**CLIP LEAD SETS**



24 AWG

Set of 10 18" clip leads with 31mm insulated clips. 24 AWG stranded wires. Colors: 2 red, 2 black, 2 green, 2 yellow, 2 white

**33-210-0** Bulk set 10  
**33-210-10** Display Pkg

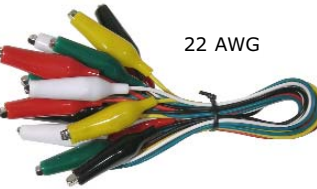

22 AWG

Set of 10 heavy duty 24" clip leads with 50mm clips. 5 different colors.

**33-220-0** Bulk set 10  
**33-220-10** Display Pkg


**NATURAL NYLON CABLE TIES**



High quality nylon cable ties available in bags of 1000 or smaller quantity display packages.

	<b>Length</b>	<b>Width</b>	<b>Load</b>
<b>34-121-100</b>	3.5" (90mm)	2.4mm	8 Kg
<b>34-121-1000</b>			
<b>34-122-100</b>	4" (100mm)	2.5mm	8 Kg
<b>34-122-1000</b>			
<b>34-123-100</b>	5.5" (140mm)	3.6mm	18Kg
<b>34-123-1000</b>			
<b>34-124-100</b>	7.5" (188mm)	4.8mm	22Kg
<b>34-124-1000</b>			
<b>34-125-100</b>	8" (200mm)	4.8mm	22Kg
<b>34-125-1000</b>			
<b>34-126-50</b>	11" (300mm)	4.8mm	22kg
<b>34-126-1000</b>			

Note: -1000 are bulk packages of 1,000. Others are Display Packages.

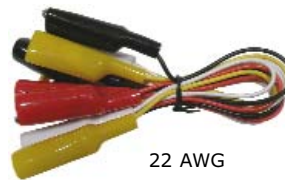

22 AWG

Set of 4 heavy duty 30" clip leads with 50mm clips. Colors: black, red, yellow, white.

**33-230-0** Bulk set 4  
**33-230-4** Display Pkg

**SEIZER PROBES (55mm)**



**33-361-0** Black  
**33-362-0** Red  
**33-360-2** Pkg  
1 red 1 black

**32mm ALLIGATOR CLIPS**



**33-400-0** Bulk  
**33-400-10** Pkg (10)

**32mm INSULATED ALLIGATOR CLIPS**



Note: The 33-409-0 contains 10 clips in 5 colors, the -10 is a display package of 10.

**33-409-0** Bulk set 10  
**33-409-10** Pkg (10)

**40mm INSULATED ALLIGATOR CLIPS**



**33-411-0** Bulk black  
**33-412-0** Bulk red  
**33-419-10** Pkg 5 red/black

**51mm ALLIGATOR CLIPS (with screw)**



**33-430-0** Bulk  
**33-430-10** Pkg (10)

**51mm INSULATED ALLIGATOR CLIPS**



**33-431-0** Bulk black  
**33-432-0** Bulk red  
**33-439-10** Pkg 5 red/black

**NATURAL COLOR CABLE TIES**



Colored, high quality nylon cable ties. Load: 8Kg

	<b>Length</b>	<b>Width</b>	<b>Color</b>
<b>34-122BL-100</b>	4" (100mm)	2.5mm	Blue
<b>34-122BL-1000</b>	4" (100mm)	2.5mm	Blue
<b>34-122GN-100</b>	4" (100mm)	2.5mm	Green
<b>34-122GN-1000</b>	4" (100mm)	2.5mm	Green
<b>34-122RD-100</b>	4" (100mm)	2.5mm	Red
<b>34-122RD-1000</b>	4" (100mm)	2.5mm	Red
<b>34-122YL-100</b>	4" (100mm)	2.5mm	Yellow
<b>34-122YL-1000</b>	4" (100mm)	2.5mm	Yellow