

## PART#/PRODUCT SEARCH

47-406-0

GO &gt;&gt;

[Item Index](#)

- Mode Catalog
- Lenline Part# Convert
- AC Adapters
- Audio Products
- Battery Holders
- Bottles and Dispensers
- Brushes
- Buzzers/Alarms
- CATV Products
- Circuit Breakers
- Coaxial Connectors
- Computer Accessories
- Connectors
- DC Power Products
- Earphones/Microphones
- Fans
- Fuseholders/Fuses
- Hardware
- IC Sockets
- Knobs
- LED Products
- Lamps/Pilot Lamps
- Miscellaneous Items
- Plastic Boxes
- Potentiometers/L-Pads
- Power Cords/Jacks/Bars
- RF Adapters
- Relays
- Rubber Feet/Grommets
- Speakers/Speaker Wire
- Switches
- Telephone Products
- Test Equipment
- Tool Cases
- Tools
- Transformers
- Video Products
- Wiring Products
- Latent Fingerprint Brush**


RoHS  
compliant

Enlarge

## MICRO SWITCH

15A @ 125VAC or 250VAC

**Contact resistance: 15mΩ maximum (initial)**  
**Insulation resistance: 100MΩ min (@ 500VDC)**  
**Dielectric strength: 1,000VAC for 1 minute**  
**Service life mechanical: 10,000,000 oper. min.**  
**Service life electrical: 100,000 oper. min. (full load)**  
**Operating temperature: -20°C to 75°C**  
**Operating force: 230g max. (without lever)**

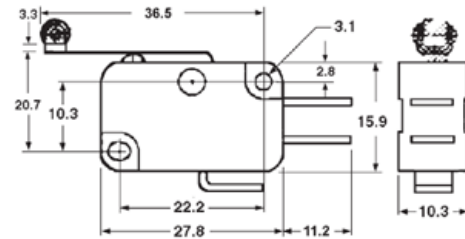

25.9mm roller actuator

**47-406-0** Bulk  
**47-406-1** Display Pkg

