

PART#/PRODUCT SEARCH

50-533-0


GO >>

[Item Index](#)

- Mode Catalog
- Lenline Part# Convert
- AC Adapters
- Audio Products
- Battery Holders
- Bottles and Dispensers
- Brushes
- Buzzers/Alarms
- CATV Products
- Circuit Breakers
- Coaxial Connectors
- Computer Accessories
- Connectors
- DC Power Products
- Earphones/Microphones
- Fans
- Fuseholders/Fuses
- Hardware
- IC Sockets
- Knobs
- LED Products
- Lamps/Pilot Lamps
- Miscellaneous Items
- Plastic Boxes
- Potentiometers/L-Pads
- Power Cords/Jacks/Bars
- RF Adapters
- Relays
- Rubber Feet/Grommets
- Speakers/Speaker Wire
- Switches
- Telephone Products
- Test Equipment
- Tool Cases
- Tools
- Transformers
- Video Products
- Wiring Products
- Latent Fingerprint Brush**

10 AMP PC RELAY

Contact Res.: 50mΩ max.
Operate Time: 10ms max.
Release Time: 4ms max.
Insulation Res.: 100MΩ min.
Mechanical Life: 100M cycles
Electrical Life: 100K cycles
Resistive Load: 10A@28VDC or 10A@125VAC
Inductive Load: 3A@28VDC or 3A@125VAC

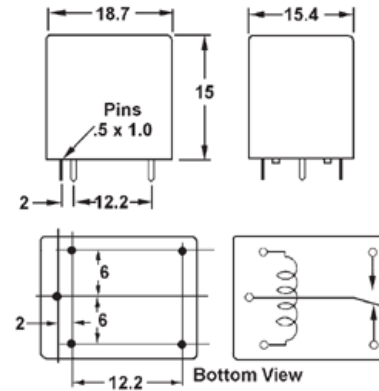

Circuitry SPDT
Oper. Voltage 12VDC
Coil Resistance 400Ω

50-533-0 Bulk
50-533-1 Display Pkg

