

PART#/PRODUCT SEARCH

55-111Y-0

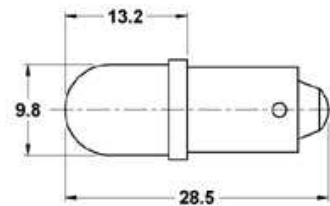
GO >>

[Item Index](#)

[Mode Catalog](#)
[Lenline Part# Convert](#)
[AC Adapters](#)
[Audio Products](#)
[Battery Holders](#)
[Bottles and Dispensers](#)
[Brushes](#)
[Buzzers/Alarms](#)
[CATV Products](#)
[Circuit Breakers](#)
[Coaxial Connectors](#)
[Computer Accessories](#)
[Connectors](#)
[DC Power Products](#)
[Earphones/Microphones](#)
[Fans](#)
[Fuseholders/Fuses](#)
[Hardware](#)
[IC Sockets](#)
[Knobs](#)
[LED Products](#)
[Lamps/Pilot Lamps](#)
[Miscellaneous Items](#)
[Plastic Boxes](#)
[Potentiometers/L-Pads](#)
[Power Cords/Jacks/Bars](#)
[RF Adapters](#)
[Relays](#)
[Rubber Feet/Grommets](#)
[Speakers/Speaker Wire](#)
[Switches](#)
[Telephone Products](#)
[Test Equipment](#)
[Tools/Tool Cases](#)
[Transformers](#)
[Video Products](#)
[Wiring Products](#)
[Latent Fingerprint Brush](#)

LED REPLACEMENT LAMP T3 1/4 (10mm) Bayonet Base

Energy efficient, long lasting led replacement bulbs are suitable replacements for T3 1/4 (10mm) Bayonet Base Lamps. They are not affected with high vibration or harsh conditions like incandescent bulbs. These replacement bulbs will operate on either AC or DC voltage.

RoHS
compliant

Color Yellow
Volts 12V AC/DC
Brightness 2000 mcd
Forward Current 20 mA
15V Max

55-111Y-0 Bulk
55-111Y-1 Display Pkg