

PART# / PRODUCT SEARCH

55-214R-0

GO >>

[Item Index](#)

Mode Catalog

Lenline Part# Convert

AC Adapters

Audio Products

Battery Holders

Bottles and Dispensers

Brushes

Buzzers/Alarms

CATV Products

Circuit Breakers

Coaxial Connectors

Computer Accessories

Connectors

DC Power Products

Earphones/Microphones

Fans

Fuseholders/Fuses

Hardware

IC Sockets

Knobs

LED Products

Lamps/Pilot Lamps

Miscellaneous Items

Plastic Boxes

Potentiometers/L-Pads

Power Cords/Jacks/Bars

RF Adapters

Relays

Rubber Feet/Grommets

Speakers/Speaker Wire

Switches

Telephone Products

Test Equipment

Tools/Tool Cases

Transformers

Video Products

Wiring Products


Latent Fingerprint Brush

RoHS
compliant



SUPER BRIGHT LED REPLACEMENT 120V AC/DC LAMP T3 1/4 (10mm) Bayonet Base

These LED lamps are suitable long life replacements for T3 1/4 bayonet base lamps. With internal resistor for the specified voltage. These replacement bulbs will operate on either AC or DC voltage.

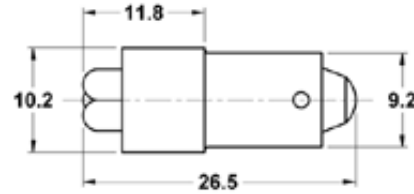

| | |
|------------------------|------------|
| Color | Red |
| Volts | 120V AC/DC |
| Brightness | 3500 mcd |
| Forward Current | 4.8 mA |
| 120V Max | |

55-214R-0 Bulk
55-214R-1 Display Pkg

