

## PART#/PRODUCT SEARCH

61-301-1

GO &gt;&gt;

[Item Index](#)


- Mode Catalog
- Lenline Part# Convert
- AC Adapters
- Audio Products
- Battery Holders
- Bottles and Dispensers
- Brushes
- Buzzers/Alarms
- CATV Products
- Circuit Breakers
- Coaxial Connectors
- Computer Accessories
- Connectors
- DC Power Products
- Earphones/Microphones
- Fans
- Fuseholders/Fuses
- Hardware
- IC Sockets
- Knobs
- LED Products
- Lamps/Pilot Lamps
- Miscellaneous Items
- Plastic Boxes
- Potentiometers/L-Pads
- Power Cords/Jacks/Bars
- RF Adapters
- Relays
- Rubber Feet/Grommets
- Speakers/Speaker Wire
- Switches
- Telephone Products
- Test Equipment
- Tool Cases
- Tools
- Transformers
- Video Products
- Wiring Products
- Latent Fingerprint Brush**

RoHS  
compliant

Enlarge

## PANEL MOUNT AUDIO ALARM

Current: 15mA  
Sound output: 80db @ 100cm  
Frequency: 2.9KHz

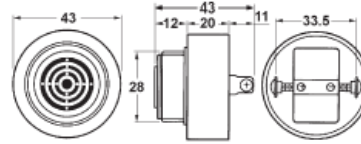

Input voltage 6 ~ 28 VDC

Tone output Continuous tone

61-301-0 Bulk  
61-301-1 Display Pkg

