



Modular industrial switches that can be assembled to meet any customer requirement. This modular system allows the distributor to customize a switch with any combination of actuators, normally open or normally closed switches in any combination and number of poles. The picture below shows how these switches can be assembled into virtually any configuration. These are 22 mm mounting diameter. All these items when used as an assembly are UL, CSA, TUV and CE approved.

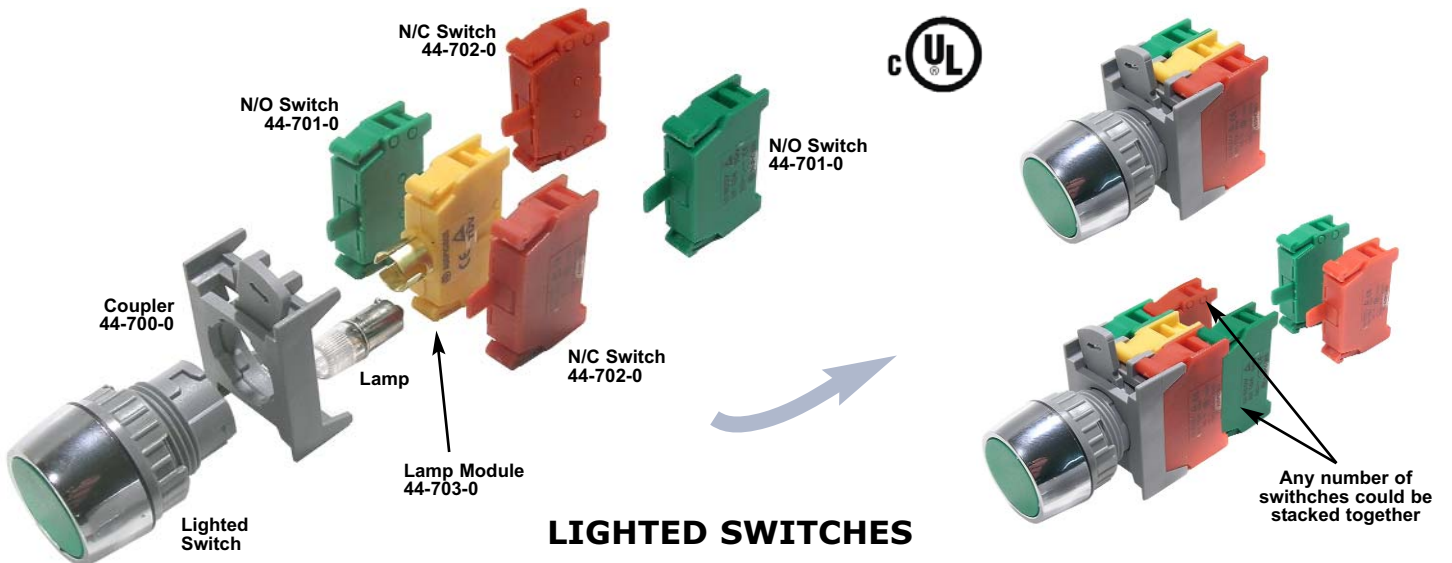

COMMON PARTS (USED ON ALMOST EVERY SWITCH)

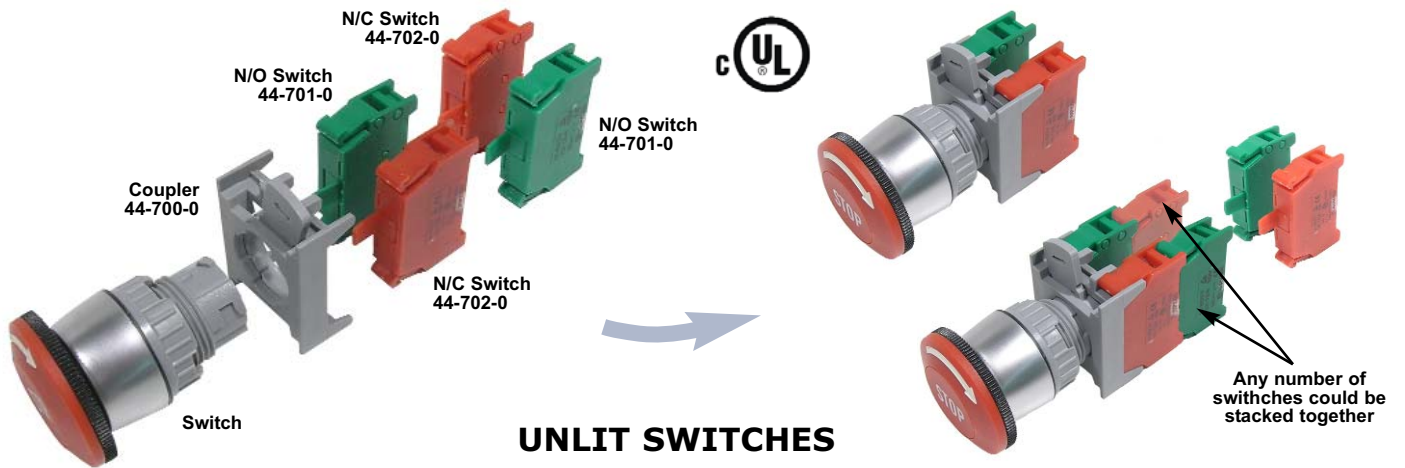

COUPLER

This coupler locks onto the actuator and is used for mounting the switch modules and the lamp module.

44-700-0



N/O SWITCH

Normally open switch module has the following CSA/UL ratings:

6.0A/120VAC	2.2A/120VDC	1.2A/600VDC
3.0A/240VAC	1.1A/240VDC	
1.5A/480VAC	0.4A/480VDC	

44-701-0



N/C SWITCH

Normally closed switch module has the following CSA/UL ratings:

6.0A/120VAC	2.2A/120VDC	1.2A/600VDC
3.0A/240VAC	1.1A/240VDC	
1.5A/480VAC	0.4A/480VDC	

44-702-0



LAMP MODULE

This module is used with any lit style actuator and will accommodate a T 3/4 bayonet base incandescent or LED lamp.

44-703-0

ACTUATORS (NO LIGHT)



Unlit momentary contact flush button (22mm diameter) actuator available in red and green.

44-705R-0 Red
44-705G-0 Green



Unlit momentary contact raised button actuator with separate red, green and yellow caps (22mm diameter). Waterproof.

44-706-0 Actuator only
44-706R(G)(Y)-0 Caps

* Shown with 44-706R-0 cap



Unlit momentary contact actuator with a 40mm diameter red button.

44-708R-0



Unlit panic stop actuator - 36mm locking button - must twist the black ring behind the red button to release.

44-710R-0



Red lever actuator: 3-position lever actuator. Left or right position can activate either a normally open or normally closed switch. Center position off.

44-730-0 3-position lever
44-729-0 2-position lever



Key actuator: 3-position key actuator. Left or right position can activate either a normally open or normally closed switch. Center position off.

44-740-0

ACTUATORS (LIGHTED)



Lighted momentary contact flush button (22mm diameter) available in red and green.

44-720R-0 Red
44-720G-0 Green



Lighted momentary contact raised button actuator with separate red, green and yellow caps (22mm diameter). Waterproof.

44-706-0 Actuator only
44-721R(G)(Y)-0 Caps

* Shown with 44-721R-0 cap



Lighted momentary contact 40mm large button actuator available with separate red, green and yellow 40mm caps.

44-706-0 Actuator only
44-714R(G)(Y)-0 Caps

* Shown with 44-714R-0 cap



Lighted alternate action flush button (22mm diameter) actuator (available in red with white circle only)

44-725R-0




Lighted alternate action 36mm large button actuator available with separate red and green caps.

44-727-0 Actuator only
44-727R(G)-0 Caps

* Shown with 44-727R-0 cap

GENERAL SPECIFICATION

Ambient temperature: -20°C ~ 60°C
Contact resistance: 50mΩ max.
Dielectric life: 2500V AC 1 min (between live and dead parts).
Full voltage units: 1000V AC 1 min.
Electric life: 500.000 operating frequency 30 operations/min
Duty rate 40%

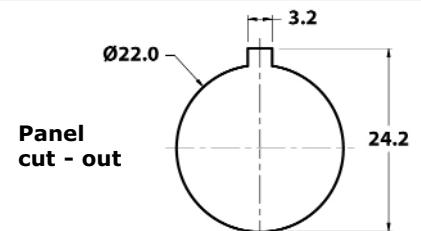

*** SPECIAL NOTE ***

If you require another style of actuator not show here. please contact us as there are many other styles available.