

SPEAKER TERMINALS



4 push type terminals, color coded for any audio application. Overall size: 75mm x 20mm. Mounting holes 64mm centre to centre.

58-094-0 Bulk
58-094-1 Package



Phenolic mounted push-type speaker terminals. 23 W x 50 L 39.5 mm mtg. holes.

58-098-0 Bulk
58-098-2 Package



Push type speaker terminals 20 W x 55 L 45mm mtg. holes

58-099-0 Bulk
58-099-2 Package

TERMINAL BLOCKS

SPECIFICATIONS


Materials:

Housing: Polyamid 6.6
Terminals: Tin plated brass
Contacts: Nickel plated brass

Electrical:

Ratings: 8A @ 300 Volts
Wire size: 14 AWG maximum

These lock together forming a continuous 5mm spacing terminal block

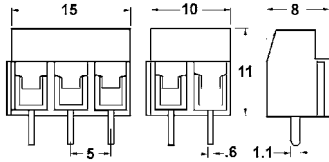

58-102-0 Bulk 2-position
58-102-3 Package (3)
58-103-0 Bulk 3-position
58-103-2 Package (2)



SPECIFICATIONS


Materials:

Housing: Polyamid 6.6
Terminals: Tin plated brass
Contacts: Nickel plated brass

Electrical:

Ratings: 10 Amp @ 300 V
Wire size: 14 AWG maximum

These lock together forming a continuous 5mm spacing terminal block

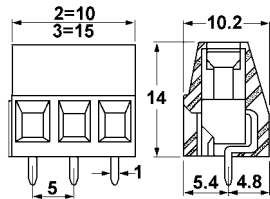

58-112-0 Bulk 2-position
58-112-3 Package (3)
58-113-0 Bulk 3-position
58-113-2 Package (2)




TERMINAL BLOCKS

These 12 position flexible terminal blocks can be cut to length.




3 Amp

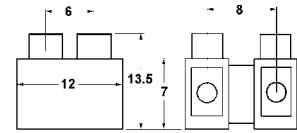


58-301-0 Bulk
58-301-2 Package




6 Amp

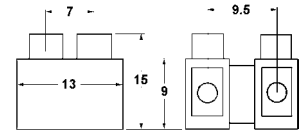

58-302-0 Bulk
58-302-2 Package

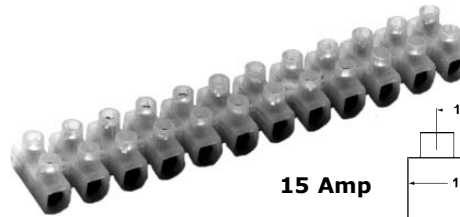

15 Amp

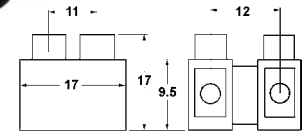


58-303-0 Bulk
58-303-1 Package

These flexible 12-position terminal blocks with wire protectors are made of Nylon 66, UL94V2 and are approved by most agencies including CSA, UL, VDE, OVE.




Current: UL 20 Amps/600V
CSA 10 Amps/400V
Wire: UL 12-22 AWG
CSA 18-20AWG

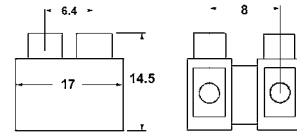

58-308-0 Bulk
58-308-1 Pkg



Current: UL 30 Amps/600V
CSA 20 Amps/400V
Wire: UL 10-22 AWG
CSA 14-18AWG

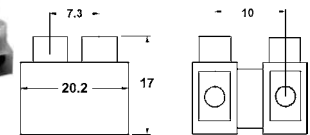

58-312-0 Bulk
58-312-1 Pkg



We have many different types of terminal blocks available on special order. If you have a requirement, please contact Main Electronics for details and order quantities.

Visit our Web Site at www.mainelectronics.com