



AUDIO TRANSFORMERS

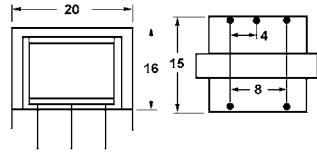


Primary: 500Ω center-tapped Secondary: 8Ω Bulk
60-281-0

Primary: 1.2KΩ center-tapped Secondary: 8Ω Bulk
60-282-0
 Use -1 for Display Package

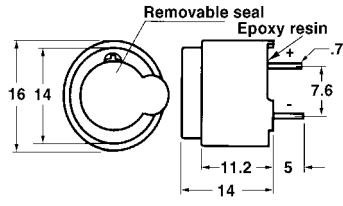


Electro-magnetic transducer. **Requires external circuitry.**
 Current: 25mA
 Output: 88db @ 10cm
 Freq.: 2KHz
61-221-0 4-9 VDC
 Use -1 for Display Package

600Ω : 600Ω TRANSFORMER

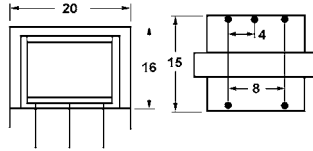

Center pin on primary side is an electrostatic shield.

Primary: 600Ω
 Secondary: 600Ω
 Freq. response: 300Hz - 3500Hz
 Max. current: 160mA
60-606-0 Bulk
60-606-1 Display Package

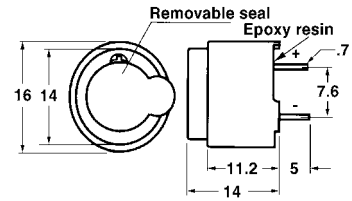



Magnetic buzzer. Complete with internal driver.
 Current: 30mA
 Output: 85db @ 10cm
 Freq.: 2KHz
61-223-0 4-8 VDC
61-224-0 8-15 VDC
 Use -1 for Display package

AUDIO L PADS




8 ohm 15 watt balanced impedance audio level control.

61-111-0 Mono Bulk
61-112-0 Stereo Bulk
 Use -1 for Display Package

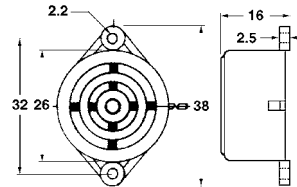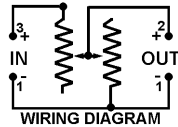

Panel mount buzzer with 100mm leads.
 Current: 40mA
 Output: 90db @ 30cm
 Freq.: 2800 Hz
61-231-0 4-8 VDC
61-232-0 8-16 VDC
61-233-0 20-28 VDC
 Use -1 for Display Package

BUZZERS

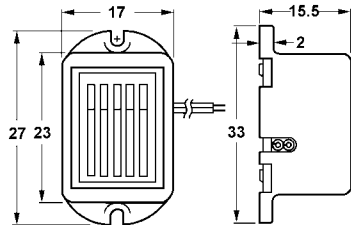


Solid state buzzer 100mm leads
 Current: 35mA
 Sound output: 85db @ 20cm
 Frequency: 2KHz

61-211-0 4-8VDC
61-212-0 8-16VDC
 Use -1 for Display Package



Panel mount audio alarms.
 Input voltage: 4-28 VDC *
 Current: 15mA
 Output: 80db @ 100cm
 Freq.: 3.2KHz

The 61-303-0 has dual output. Continuous and Pulsed.

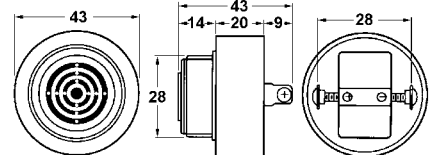

New Item **61-301-0** Continuous tone
61-302-0 Pulsed tone
61-303-0 Cont. & Pulsed
 Use -1 for Display Package **New Item**

The buzzers shown in this catalog are our most popular types. If you require a different style, please contact us for price and availability.

* 61-303-0 Input Voltage - 16VDC Maximum