


SGR-36

For use on 92 mm sq. fans
RoHS Compliant

.xxx ± 0.005 .xx ± 0.02 ANG. ± 1.5"

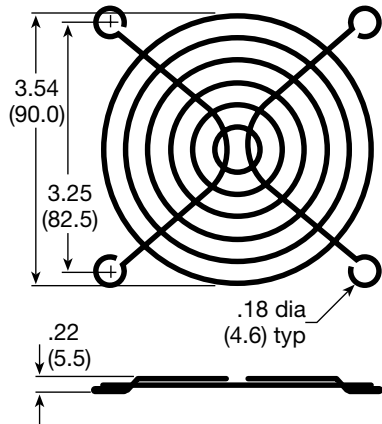

- Bright nickel chrome plated finish 0.0005.
- Meets UL 0.25 inch maximum spacing plug gage test.
- Steel wire rings 1.6 mm (0.063") D., ribs 1.8 mm (0.072") D., bright basic wire.
- Weld joints to withstand minimum of 220 lbs. separation force.

