
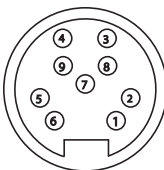
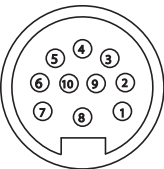


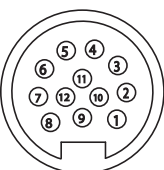

MIN Series Size III Cordsets

North American Color Code ❖ PVC Cable ❖ 18 AWG 300V Plugs

MIN Series Size III Cordsets

Face View of Male	# of Poles	Color Code	Wire AWG Rating	Length	Female Plugs	Male Plugs
	9	1-Orange 2-Blue 3-Red w/ Black 4-Green w/ Black 5-White 6-Red 7-Green/Yellow 8-White w/ Black 9-Black	18 300V 4A	3 FT 6 FT 12 FT 20 FT 30 FT	MIN-9FPX-3 MIN-9FPX-6 MIN-9FPX-12 MIN-9FPX-20 MIN-9FPX-30	MIN-9MPX-3 MIN-9MPX-6 MIN-9MPX-12 MIN-9MPX-20 MIN-9MPX-30
	10	1-Orange 2-Blue 3-White w/ Black 4-Red w/ Black 5-Green w/ Black 6-Orange w/ Black 7-Red 8-Green/Yellow 9-Black 10-White	18 300V 4A	3 FT 6 FT 12 FT 20 FT 30 FT 50 FT	MIN-10FPX-3 MIN-10FPX-6 MIN-10FPX-12 MIN-10FPX-20 MIN-10FPX-30 MIN-10FPX-50	MIN-10MPX-3 MIN-10MPX-6 MIN-10MPX-12 MIN-10MPX-20 MIN-10MPX-30
	12	1-Orange 2-Blue 3-White w/ Black 4-Red w/ Black 5-Green w/ Black 6-Orange w/ Black 7-Blue w/ Black 8-Black w/ White 9-Green/Yellow 10-Red 11-White 12-Black	18 300V 4A	3 FT 6 FT 12 FT 20 FT 30 FT 50 FT	MIN-12FPX-3 MIN-12FPX-6 MIN-12FPX-12 MIN-12FPX-20 MIN-12FPX-30 MIN-12FPX-50	MIN-12MPX-3 MIN-12MPX-6 MIN-12MPX-12 MIN-12MPX-20 MIN-12MPX-30

For Stainless Steel coupling nut, add a "-SS" suffix (e.g. MIN-9FPX-6 becomes MIN-9FPX-6-SS).

Specifications:

- Body: Oil Resistant Yellow PVC
- Contacts: Copper Alloy with Gold Plating
- Coupling Nut: Clear Anodized Aluminum
- Cable: Oil Resistant Yellow PVC Jacket,
Rated at 300V, 105°C, Non-Wicking,
Non-Hygroscopic, AWM Style 2661
- Conductors: 18 AWG Bare Copper, PVC Insulated
- Temperature: -40°C to +105°C (-40°F to +221°F)
- Protection: IP 67
- Approvals: U.S.: UL Recognized
Canada: C-UL Recognized

