



# Ring Tongues - Vinyl Insulated Butted Seam 16-14 AWG

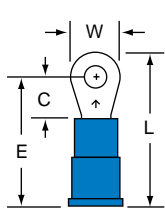


Product Number <sup>†</sup>	Wire		Stud Size	W	C	L	E	Thickness	Barrel Length	Barrel I.D.	Maximum Insulation Diameter	Terminals per Case
	UPC (054007-)	Range (AWG)										
MVU14-4R/SK	01444	16-14	4	0.25	0.22	0.80	0.67	0.030	0.25	0.090	0.170	1000
MVU14-6R/SK	01446	16-14	6	0.25	0.22	0.80	0.67	0.030	0.25	0.090	0.170	1000
MVU14-8R/SK	01449	16-14	8	0.25	0.22	0.80	0.67	0.030	0.25	0.090	0.170	1000
MVU14-8RK	01450	16-14	8	0.33	0.29	0.90	0.74	0.030	0.25	0.090	0.170	1000
MVU14-8RLK	01451	16-14	8	0.31	0.33	0.93	0.78	0.030	0.25	0.090	0.170	1000
MVU14-10RK	01452	16-14	10	0.33	0.29	0.90	0.74	0.030	0.25	0.090	0.170	1000
MVU14-10RLK	01453	16-14	10	0.31	0.33	0.93	0.78	0.030	0.25	0.090	0.170	1000
MVU14-14R/SK	01454	16-14	1/4	0.47	0.40	1.08	0.85	0.030	0.25	0.090	0.170	1000
MVU14-516R/SK	01456	16-14	5/16	0.47	0.40	1.08	0.85	0.030	0.25	0.090	0.170	1000
MVU14-38RK	01458	16-14	3/8	0.56	0.40	1.13	0.85	0.030	0.25	0.090	0.170	1000




**MVU14-4R/S**  
Stud Size 4  
Wire Range 16-14

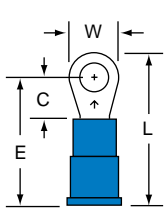


**MVU14-6R/S**  
Stud Size 6  
Wire Range 16-14

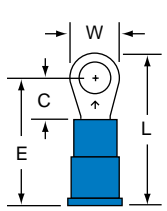


**MVU14-8R/S**  
Stud Size 8  
Wire Range 16-14

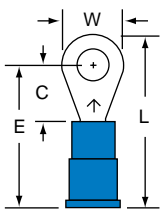


**MVU14-8R**  
Stud Size 8  
Wire Range 16-14

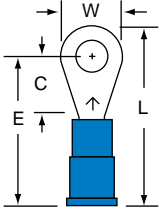


**MVU14-8R/L**  
Stud Size 8  
Wire Range 16-14

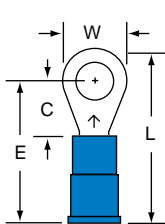


**MVU14-10R**  
Stud Size 10  
Wire Range 16-14

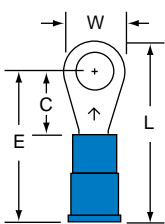


**MVU14-10R/L**  
Stud Size 10  
Wire Range 16-14

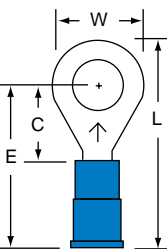

**MVU14-14R/S**  
Stud Size 1/4  
Wire Range 16-14

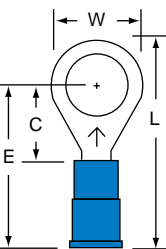

**MVU14-516R/S**  
Stud Size 5/16  
Wire Range 16-14

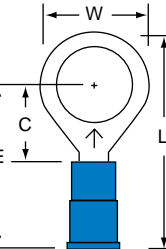

**MVU14-38R**  
Stud Size 3/8  
Wire Range 16-14

Stud Size  
Wire Range

Stud Size  
Wire Range