



All 3M Products Innovation Explore 3M

Search

United States [Change](#)

## Electrical Commercial and Industrial

[Products](#) | [Documentation & Literature](#) | [News & Tradeshows](#) | [Support](#)

[United States](#) > [All 3M Products](#) > [Market Segments](#) > [Electronics, Electrical, and Communications](#) > [Electrical Products](#) > [Electrical Commercial and Industrial](#) > [Products](#) > [Electrical Commercial & Industrial Products Catalog](#) > [Terminals, Kits and Tools](#) > [Terminals](#) > [3M™ Highland™ Female Disconnects](#) > [3M™ Highland™ Nylon Fully Insulated Female Disconnect Terminal FDI18-250Q, AWG 22-18, 25/bag](#)


[Find An Account Rep](#)

[Where To Buy \(Find A Distributor\)](#)

[Contact Us](#)

# 3M™ Highland™ Nylon Fully Insulated Female Disconnect Terminal FDI18-250Q, AWG 22-18, 25/bag

3M ID 80611602642 UPC# 00051128600030 3M Product Number FDI18-250Q

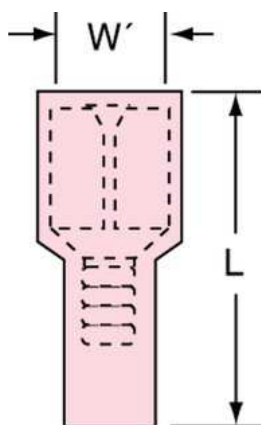

### Network Access Message: The page

This female disconnect accepts a wire range of 22-18 AWG, a stud size of .250 and has a case quantity of 10 bags.

[Print](#)

### Need Help?

[Share](#)

**Questions?** We can help  
[Contact Us](#)

[Overview](#) | [Support](#)

### Specifications

Agency Approvals	UL and CSA
Barrel Inside Diameter	0.08 Inch
Barrel Length	0.25 Inch
Barrel Style	Butted
Brand	Highland
Conductor Sizes	22 - 18 AWG
CSA File Number	LR22190
Diameter (D)	0.23 Inch
Fastener Orientation	Female
Insulation Material	Nylon
Length (L)	0.87 Inch
Mates with Male Tab Width (W')	0.25 Inch
Maximum Insulation Outer Diameter	0.145 Inch
Packaging	25 per bag
Pad Width	0.25 Inch
Terminal Style	Fully Insulated
Terminal Type	Disconnect
Thickness	0.032 Inch
UL File Number	E70512
Width (W)	0.37 Inch

[Legal Information](#) | [Privacy Policy](#)

