

Solutions for Electronic Specialty Markets (ESM)


Product Catalog for Electronic Specialty Markets

- 3M Electronic Specialty Markets New Product Releases
- 3M Abrasives
- 3M Adhesives, Cleaners & Compounds
- 3M Breadboards & Test Clips
- 3M Cable & Assemblies
- 3M Copper Interconnects
- 3M Fiber Optics
- 3M Fire Protection
- 3M Heat Shrink
- 3M Identification Systems
- 3M Occupational Health & Safety Products
- 3M Protective Bumpers
- 3M Reclosable Fasteners
- 3M Splicing, Terminating & Ducting
- 3M Static Control
- 3M Tapes
- 3M Terminals, Kits & Tools**
- 3M Vacuums & Accessories
- 3M Warehousing & Packaging Supplies
- 3M Wire Connectors

[Product Catalog for Electronic Specialty Markets](#) [3M Terminals, Kits & Tools](#) [Ring Tongues](#)
[Scotchlok Ring Tongue Terminals](#) - [Nylon Insulated Brazed Seam](#)

3M Scotchlok Nylon Insulated Brazed Seam Ring Tongue Terminal MN8 -10R/SK, Stud Size 10

[Printer-friendly format](#)

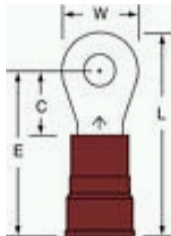

This terminal has a wire range of 8 AWG and a stud size of 10. It comes in quantities of 200 per case.

[\[click to enlarge\]](#)

GTIN(UPC/EAN) : 0 00 54007 08267 5
 3M Id : 80 - 0080 - 0603 - 5

Additional Information

 
A ring is the standard style of tongue. The safest and most reliable; it cannot be removed unless mounting screw is removed.

Learn More . . .

- [Packaging Data](#)
- [Ring Tongues - Nylon Insulated Brazed Seam 4 AWG - Product Selection Guide \(PDF 24.8 K\)](#)
- [Ring Tongues - Nylon Insulated Brazed Seam 8 AWG - Product Selection Guide \(PDF 26.1 K\)](#)
- [Scotchlok Terminals MN8 - 10R/S THRU MN4 - 12R/S - Data Sheet \(PDF 24.3 K\)](#)
- [Terminal Stud Size Chart - Product Selection Guide \(PDF 5.2 K\)](#)

Please Note:

Adobe® Acrobat® Reader is required to view PDF documents.



Other Tools

- What's New
- Sales Contacts
- U.S. Distributors

Search This Product Catalog

By Keyword

Characteristics

| | |
|-------------------------------|------------------------------|
| Agency Approvals | UL and CSA |
| Barrel Style | Brazed |
| China RoHS - Below MCV | Yes |
| CSA File Number | LR22190 |
| EPC Can View | Public |
| EU RoHS Compliant | Yes |
| Insulation Material | Nylon |
| Stud Size | 10 American Wire Gauge (AWG) |
| Terminal Style | Standard |
| Terminal Type | Ring |
| UL File Number | E23438 |
| Wire Gauge | 8 American Wire Gauge (AWG) |