

Search This Product Catalog


By Keyword ▼

- Utilities & Telecommunications
- Product Catalog for Utilities & Telecommunications
 - Electrical and Electronic Solutions for OEM
 - Electrical Products**
 - Static Control Solutions

[Product Catalog for Utilities & Telecommunications](#) > [Electrical Products](#) > [Wire Terminals and Connectors](#) > [3M™ Scotchlok™ Male Disconnects](#) >

3M™ Scotchlok™ Fully Nylon Insulated Butted Seam Male Disconnect MNU18-187DMIK, 22-18 AWG

[Printer-friendly format](#)

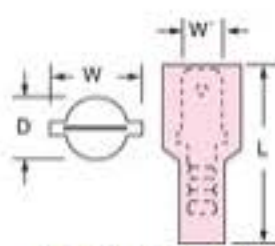

This terminal has a wire range of 22-18 AWG and has case quantities of 1000 ea/carton.

[\[click to enlarge\]](#)

3M Id : 80-6100-6480-2

GTIN(UPC/EAN) : 0 00 54007 02379 1

Additional Information

The disconnects are attached to mating part by tongue of female part slipping over male tab. The use of dents and rolled edges on female part provides excellent holding force while allowing easy and quick disconnect.

Learn More . . .

[Packaging Data](#)

Characteristics

Agency Approvals	UL and CSA
Barrel Inside Diameter	0.08 Inch
Barrel Length	0.24 Inch
Barrel Style	Butted
Brand	Scotchlok
Conductor Sizes	22 - 18 AWG
CSA File Number	LR22190
Diameter (D)	0.3 Inch
Fastener Orientation	Male
Insulation Material	Nylon
Length (L)	0.87 Inch
Male Tab Width (W')	0.187 Inch
Maximum Insulation Outer Diameter	0.145 Inch
Packaging	1000 per bulk box
Pad Width	0.187 Inch
RoHS 2011/65/EU Compliant	Yes
Terminal Style	Fully Insulated
Terminal Type	Disconnect
Thickness	0.02 Inch
UL File Number	E70512
Width (W)	0.37 Inch