

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0022012237](#)  
**Status:** **Obsolete**  
**Overview:** [kk](#)  
**Description:** 2.54mm (.100") Pitch KK® Crimp Terminal Housing, Friction Ramp, 23 Circuits, Use with 2759|6459|41572

**Documents:**  
[Drawing \(PDF\)](#)

**Agency Certification**

CSA	LR19980
UL	E29179

**General**


Product Family	Crimp Housings
Series	<a href="#">2695</a>
Application	Signal
Overview	<a href="#">kk</a>
Product Name	KK®

**Physical**

Circuits (maximum)	23
Color - Resin	Natural (White)
Flammability	94V-0
Gender	Female
Glow-Wire Compliant	No
Lock to Mating Part	Yes
Material - Resin	Nylon
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.54mm (.100")
Pitch - Termination Interface	2.54mm (.100")
Stackable	No
Temperature Range - Operating	0°C to +75°C

**Material Info**

Old Part Number	2695-23R
-----------------	----------

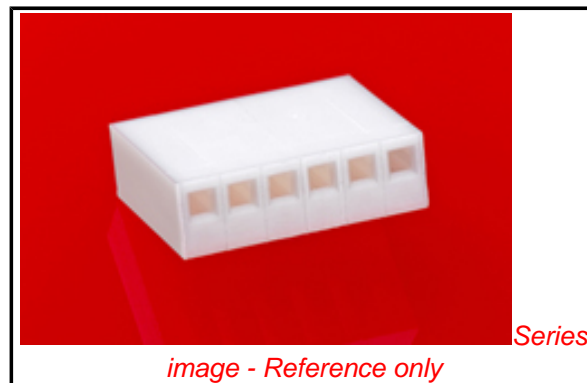

*image - Reference only*

**EU RoHS**

**ELV and RoHS Compliant**  
**REACH SVHC Contains SVHC: No**  
**Low-Halogen Status**  
**Low-Halogen**

**China RoHS**



**Need more information on product environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

**Search Parts in this Series**

[2695Series](#)

**Mates With**

2.54mm (.100") Pitch KK® PCB Headers  
[42375](#) , [42377](#) , [42376](#) , [4030](#) , [6373](#) , [6410](#)

**Use With**

KK® Crimp Terminal [2759](#) , [6459](#) , [41572](#)

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**