

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0391701126](#)
Status: **Obsolete**
Description: Interface Module, Ribbon Cable Connector to Eurostyle™ Pluggable, 26 Circuits, with DIN Rail Adapter Unit

Documents:
[Drawing \(PDF\)](#)

General

Product Family	Terminal Blocks
Series	39170
Application	Wire-to-Wire
Comments	Ribbon Cable connector
Component Type	One Piece
Product Name	Eurostyle™ Pluggable, Ribbon
Type	Interface Module

Physical

Circuits (Loaded)	26
Entry Angle	180° Angle
Lock to Mating Part	None
Number of Rows	2
Orientation	Vertical
PCB Retention	None
Panel Mount	No
Pitch - Mating Interface	5.08mm (.200")
Pitch - Termination Interface	5.08mm (.200")
Polarized to Mating Part	Yes
Shrouded	Fully
Stackable	No
Surface Mount Compatible (SMC)	No
Temperature Range - Operating	110°C
Wire Size AWG	12, 14, 16, 18, 20, 22, 24, 26


Electrical

Current - Maximum per Contact	15A
Voltage - Maximum	300V

Material Info

Reference - Drawing Numbers

Sales Drawing	SD-39170-006
---------------	--------------

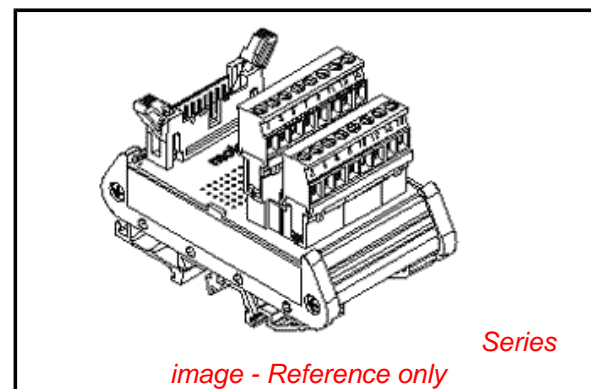

EU RoHS

RoHS Compliance

Not Required

REACH SVHC

Not Reviewed

Low-Halogen Status

Not Reviewed

China RoHS

Need more information on product environmental compliance?

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

[39170Series](#)