

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0451361001](#)
Status: **Active**
Overview: [Mega-Fit Power Connectors](#)
Description: Mega-Fit-to-Mega-Fit Off-the-Shelf (OTS) Cable Assembly, Dual Row, 150.00mm Length, Matte Tin Plated, 10 Circuits, Black

Documents:

[Drawing \(PDF\)](#) [Product Literature \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Cable Assemblies
Series	45136
Application	Power, Wire-to-Board
Assembly Configuration	Dual Ended Connectors
Connector to Connector	Mega-Fit-to-Mega-Fit
Overmolded	No
Overview	Mega-Fit Power Connectors
Product Literature Order No	987651-6143
Product Name	Mega-Fit
Type	Discrete Wire Assembly, High-Power Assembly
UPC	191128777919

Physical

Cable Length	150.00mm
Circuits (Loaded)	10
Color - Resin	Black
Gender	Female-Female
Lock to Mating Part	Yes
Material - Metal	Copper Alloy
Material - Plating Mating	Matte Tin
Material - Plating Termination	Matte Tin
Material - Resin	Nylon
Net Weight	89.088/g
Number of Rows	2
Packaging Type	Bag
Pitch - Mating Interface	5.70mm
Plating min - Mating	1.524µm
Plating min - Termination	1.524µm
Single Ended	No
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	3.90mm
Wire Size AWG	12
Wire/Cable Type	UL 1015


Electrical

Current - Maximum per Contact	23.0A
Voltage - Maximum	600V

Material Info

Reference - Drawing Numbers

Sales Drawing	451361001-000
---------------	---------------

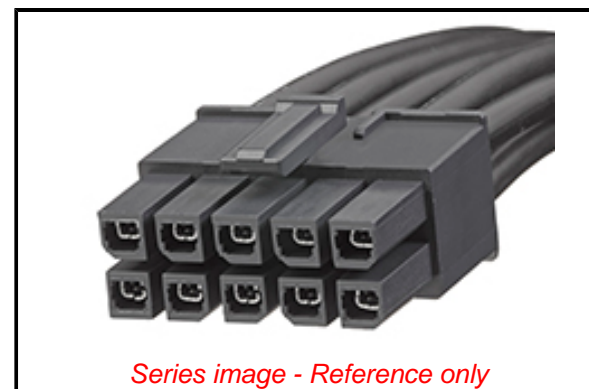

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per - ED/71/2019 (16 July 2019)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[45136 Series](#)

Mates With

Mega-Fit Header [76825](#) , [76829](#) , [172064](#) , [172065](#)