

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0734035114**
Status: **Active**
Overview: FAKRA PCB, Cable and Sealed Connection Systems
Description: 50 Ohms, FAKRA SMB Jack, Right-Angle, Through Hole, Brass Body, Keying Option E, Green

Documents:

[3D Model](#) [Product Specification PS-89675-331-001 \(PDF\)](#)
[3D Model \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Drawing \(PDF\)](#)

General

Product Family RF/Coax Connectors
Series 73403
Application Automotive
Overview FAKRA PCB, Cable and Sealed Connection Systems
Product Name FAKRA, SMB
Style PCB
Type Subminiature
UPC 883906687656
Wire/Cable Type N/A

Physical

Gender Jack
Keying to Mating Part Yes
Net Weight 4.441/g
Orientation Right Angle
PCB Mounting Through Hole
Packaging Type Tray
Panel Mount No
Panel Mount Method N/A
Reverse Polar No

Electrical

Frequency 6 GHz
Impedance 50Ω
Power / Voltage VOLTAGE: 335 Vrms@Sea Level


Solder Process Data

Duration at Max. Process Temperature (seconds) 010
Lead-freeProcess Capability SMC&WAVE
Max. Cycles at Max. Process Temperature 002
Process Temperature max. C 260

Material Info

Reference - Drawing Numbers

Product Specification PS-89675-331-001
Sales Drawing SD-73403-511-001, SD-73403-511-PKG-001, SD-73403-650-001

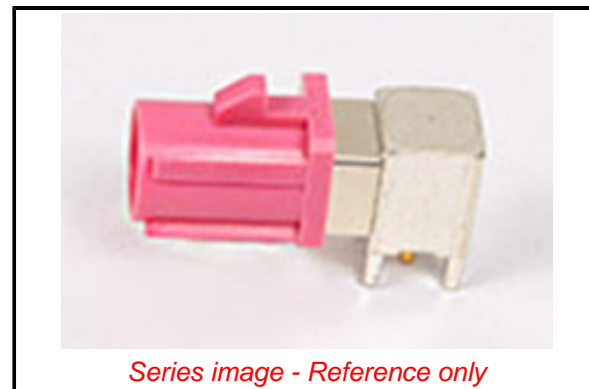

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Contained Per -
D(2020)4578-DC (25 June 2020)
Perfluorohexane-1-sulphonic acid and its salts
Perfluorononan-1-oic acid
(2,2,3,3,4,4,5,5,6,6,7 Nonadecafluorodecanoic acid (PFDA) and its sodiu
Zirconia
Aluminosilicate
Refractory Ceramic Fibr
Aluminosilicate
Refractory Ceramic Fibres
Boric acid
diisohexyl phthalate
Terphenyl, hydrogenated
1,3-propanesultone
1,2-diethoxyethane
dodecamethylcyclhexasiloxane
phenanthrene
Fatty acids, C16-18, lead salts
[phthalato(2-)]dioxotrilead
Silicic acid (H2Si2O5), barium salt (1:1), lead-
Sulfurous acid, lead salt, dibasic
cadmium hydroxide
tetralead trioxide
sulphate

China RoHS

Trilead-dioxide-
phosphonate
Lead-titanium-trioxide
lead dinitrate
cadmium
lead
cadmium oxide (non-
pyrophoric)
Boric acid, disodium
salt, hydrate

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

| | |
|-----------------|---------------|
| China ROHS | 50 Image |
| ELV | Not Relevant |
| RoHS Phthalates | Not Contained |

Search Parts in this Series

[73403](#) Series

This document was generated on 02/08/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION