

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [79575-2000](#)
Status: **Active**
Overview: iPass™ Connector System
Description: Internal iPass™ Mini SAS Cable Assembly, 26 Circuits, 30 AWG, 0.152m Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Cable Assemblies
Series	79575
Connector to Connector	Mini SAS-to-Mini SAS
Overview	iPass™ Connector System
Product Name	iPass™, PCI Express*, SAS
UPC	822350138529

Physical

Cable Length	0.152m
Circuits (Loaded)	26
Color - Resin	Black, Natural
Gender	Male-Male
Lock to Mating Part	Yes
Material - Resin	Low Density Polyethylene, Polyester
Net Weight	43.710/g
Packaging Type	Bag
Pitch - Mating Interface	0.80mm
Single Ended	No
Termination Interface: Style	Crimp or Compression
Waterproof / Dustproof	No
Wire Insulation Diameter	N/A
Wire Size AWG	30
Wire/Cable Type	Twin-ax


Electrical

Current - Maximum per Contact	1A
Shielded	Yes
Voltage - Maximum	30V AC

Material Info

Reference - Drawing Numbers

Sales Drawing	SD-79575-200
---------------	--------------

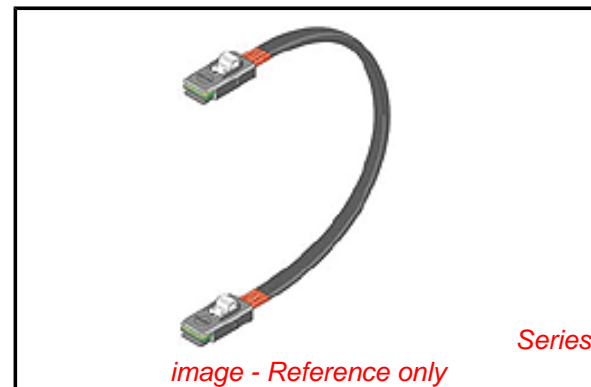

EU RoHS

**ELV and RoHS
Compliant**
**REACH SVHC
Not Reviewed**
**Low-Halogen Status
Not Reviewed**

China RoHS



**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of
 Compliance, [click here](#)

Please visit the [Contact Us](#) section for any
 non-product compliance questions.

Search Parts in this Series

[79575Series](#)

Mates With

[75783 iPass™ Right Angle Connector.](#)
[75784 iPass™ Vertical Connector](#)