

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0082245902](#)
Status: **Active**
Description: 2.54mm Pitch Round Conductor Flat Cable - 24 AWG (7 x 32) Stranded, Topcoat, 2 Circuits, Reel 30.48m Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Cable
Series	8997
Crimp Quality Equipment	Yes
Geographic Area	Asia
Product Name	Ribbon
UPC	800754371773

Physical

Cable Length	30.48m
Circuits (Loaded)	2
Insulation	PVC
Net Weight	295.564/g
Packaging Type	Reel
Pitch - Termination Interface	2.54mm
Temperature Range - Operating	-20°C to +105°C
Wire Size AWG	24
Wire/Cable Type	(7x32) Stranded, Topcoat

Electrical


Current - Maximum per Contact	N/A
Voltage - Maximum	300V

Material Info

Engineering Number	8997-02-100B
--------------------	--------------

Reference - Drawing Numbers

Sales Drawing	SD-8997-001
---------------	-------------

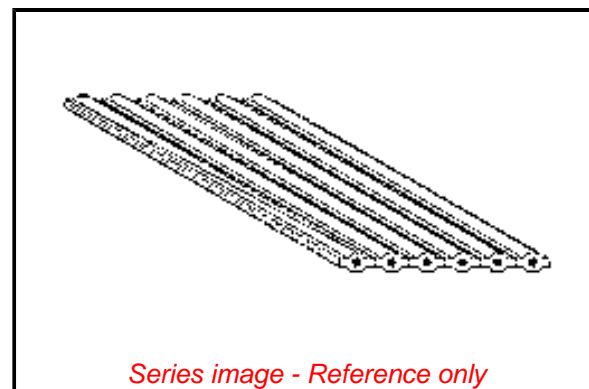

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[8997 Series](#)

Use With

[70400](#) C-Grid SL™ IDT Connector Assembly.
[70475](#) SL™ IDT Connector Assembly.
[7720](#) KK® IDT Double Cantilever Contact

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION