

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0795161041](#)
Status: **Active**
Overview: [Micro-Fit 3.0™ Connectors](#)
Description: [Micro-Fit 3.0™ Overmolded Cable Assembly, 4 Circuit, 1.0m Length](#)

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Cable Assemblies
Series	79516
Assembly Configuration	Dual Ended Connectors
Comments	When using 30 AWG current max per contact is 5A.
Connector to Connector	Micro-Fit 3.0™ Both Ends
Overview	Micro-Fit 3.0™ Connectors
Product Name	Micro-Fit 3.0™
UPC	822348120079

Physical

Cable Length	1.0m
Circuits (Loaded)	4
Color - Resin	Black
Gender	Female-Female
Lock to Mating Part	Yes
Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	Polyester, PVC
Net Weight	36.447/g
Packaging Type	Bag
Pitch - Mating Interface	3.00mm
Plating min - Mating	1.016µm
Plating min - Termination	1.016µm
Single Ended	No
Wire Insulation Diameter	N/A
Wire Size AWG	26
Wire/Cable Type	Jacketed


Electrical

Current - Maximum per Contact	3.0A
Shielded	No
Voltage - Maximum	250V

Material Info

Reference - Drawing Numbers

Sales Drawing	SD-79516-002
---------------	--------------

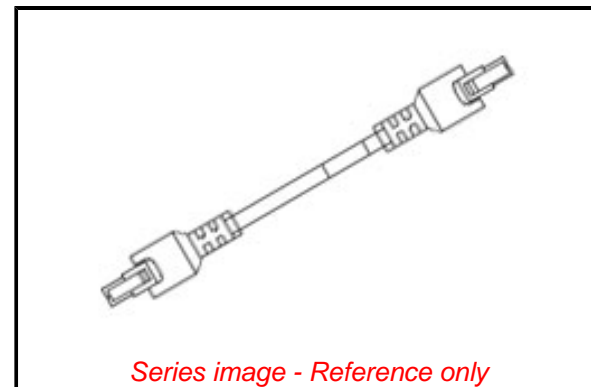

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/21/2016 (20 June
2016)

Halogen-Free

Status

Not Low-Halogen

**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[79516 Series](#)