

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0738380003**
Status: **Active**
Overview: SL™ Modular Connectors
Description: 2.54mm SL™ Crimp Housing, Single Row, Version N, TPA™ with Positive Latch, 3 Circuits

Documents:

[3D Model](#) [Packaging Specification PK-70873-0540 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-73838-005-001 \(PDF\)](#)

General

Product Family Crimp Housings
Series 73838
Application Signal, Wire-to-Board, Wire-to-Wire
Comments Terminal Position Assurance (TPA™) Piece
Overview SL™ Modular Connectors
Product Name SL™
UPC 800753951587

Physical

Circuits (maximum) 3
Color - Resin Natural
Gender Receptacle
Glow-Wire Compliant No
Material - Resin Polyester Alloy
Net Weight 0.068/g
Number of Rows 1
Packaging Type Bag
Panel Mount No
Pitch - Mating Interface 2.54mm
Stackable No
Temperature Range - Operating -40°C to +105°C


Solder Process Data

Lead-free Process Capability N/A

Material Info

Reference - Drawing Numbers

Packaging Specification PK-70873-0540
Product Specification PS-73838-005-001
Sales Drawing SD-73838-004

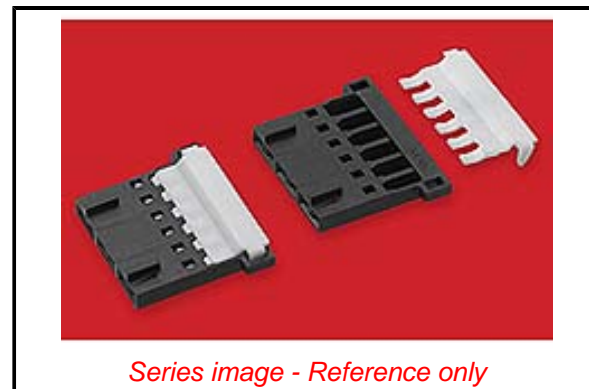

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
ED/30/2017 (7 July
2017)

Halogen-Free

Status

Not Low-Halogen

**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[73838](#) Series

Mates With

[70018](#) , [70543](#) , [70545](#) , [70553](#) , [70555](#) ,
[70107](#) Version A, [70107](#) Version B

Use With

[70058](#) , [71851](#) , [73838](#)