


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0310671040](#)
Status: **Active**
Overview: H-DAC 64™ Unsealed Connector System
Description: 2.54mm H-DAC 64™, 3 Way Male Housing Assembly, Single Row, Polarization A

Documents:

| | |
|--|--|
| 3D Model | Packaging Specification PK-30907-737 (PDF) |
| Drawing (PDF) | Packaging Specification PK-31301-076 (PDF) |
| Product Specification PS-31067-0001-001 (PDF) | RoHS Certificate of Compliance (PDF) |
| Application Specification AS-31067-100-001 (PDF) | |

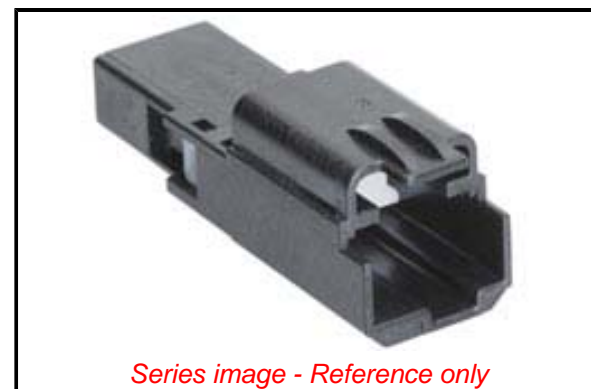

General

| | |
|----------------|-------------------------------------|
| Product Family | Crimp Housings |
| Series | 31067 |
| Application | Power, Wire-to-Board |
| Comments | Polarization Option A, Black |
| Overview | H-DAC 64™ Unsealed Connector System |
| Product Name | H-DAC 64™ |
| UPC | 800756062969 |

Physical

| | |
|-------------------------------|---------------------------------|
| Circuits (maximum) | 3 |
| Circuits Detail | 3 |
| Color - Resin | Black |
| Gender | Plug |
| Glow-Wire Compliant | No |
| Keying to Mating Part | None |
| Lock to Mating Part | Yes |
| Material - Resin | Modified Polystyrene, Polyester |
| Net Weight | 1.692/g |
| Number of Rows | 1 |
| Packaging Type | Bag |
| Panel Mount | No |
| Pitch - Mating Interface | 2.54mm |
| Pitch - Termination Interface | 2.54mm |
| Polarized to Mating Part | Yes |
| Ports | 1 |
| Stackable | No |
| Temperature Range - Operating | -40°C to +100°C |

Electrical

| | |
|-------------------------------|-------------|
| Current - Maximum per Contact | 11.0A, 9.0A |
|-------------------------------|-------------|

Solder Process Data

| | |
|-----------------------------|-----|
| Lead-freeProcess Capability | N/A |
|-----------------------------|-----|

Material Info

Reference - Drawing Numbers

| | |
|---------------------------|----------------------------|
| Application Specification | AS-31067-100-001 |
| Packaging Specification | PK-30907-737, PK-31301-076 |
| Product Specification | PS-31067-0001-001 |
| Sales Drawing | SD-31110-003 |

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/30/2017 (7 July
2017)

Halogen-Free

Status

Not Relevant

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

| | |
|-----------------|---------------|
| China ROHS | Not Relevant |
| ELV | Compliant |
| RoHS Phthalates | Not Contained |

Search Parts in this Series

[31067 Series](#)

Mates With

H-DAC 64™ 3 Way Receptacle Assembly
[31067-1010](#)

Use With

See Product Specification