

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0150150425**
Status: **Active**
Overview: Premo-Flex™ Cable Jumpers
Description: 0.30mm Pitch Premo-Flex™ Etched Polyimide Jumper, Same Side Contacts (Type A), 0.102m Cable Length, 0.12mm Cable Thickness, 25 Circuits

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-15015-001-001 \(PDF\)](#)

General

Product Family	Cable
Series	<u>15015</u>
Crimp Quality Equipment	Yes
Overview	<u>Premo-Flex™ Cable Jumpers</u>
Product Name	Premo-Flex™FFC Jumper
UPC	884982820388

Physical

Cable Length	0.102m
Circuits (Loaded)	25
Circuits (maximum)	25
Packaging Type	Bag
Pitch - Termination Interface	0.30mm
Temperature Range - Operating	-40°C to +105°C
Wire Size AWG	N/A
Wire/Cable Type	Flat Flex Cable


Electrical

Current - Maximum per Contact	0.2A
Voltage - Maximum	50V AC/DC

Material Info

Reference - Drawing Numbers

Product Specification	PS-15015-001-001
Sales Drawing	SD-15015-001

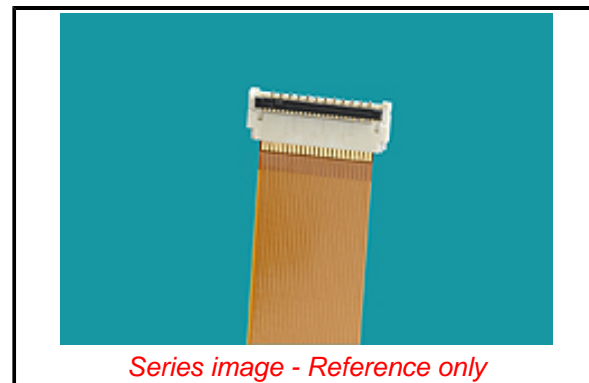

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/30/2017 (7 July 2017)

Halogen-Free

Status

Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

15015 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION