

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0191640040**
Status: **Active**
Overview: Snap Plugs and Receptacles
Description: Perma-Seal™ Male Snap Plug for 14-16 AWG Wire, Diameter 3.96mm

Documents:

[Drawing \(PDF\)](#) [Product Specification PS-19902-013-001 \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR18689
 UL E152602

General

Product Family Quick Disconnects
 Series 19164
 Crimp Quality Equipment Yes
 Insulated Partial
 Overview Snap Plugs and Receptacles
 Product Name Perma-Seal™
 Type Snap Plug
 UPC 800753113251

Physical

Barrel Type Closed
 Color - Resin Blue
 Gender Male
 Glow-Wire Compliant No
 Insulation NiAc™
 Lock to Mating Part None
 Material - Metal Copper
 Material - Plating Mating Tin
 Material - Plating Termination Tin
 Net Weight 1.343/g
 Orientation Straight
 Packaging Type Bag
 Tab Thickness N/A
 Tab Width N/A
 Temperature Range - Operating -55°C to +125°C
 Wire Insulation Diameter 6.71mm max.
 Wire Size AWG 14, 16
 Wire Size mm² 1.00-2.50

Electrical


Voltage - Maximum 600V

Material Info

Engineering Number SB-289

Reference - Drawing Numbers

Product Specification PS-19902-011-001, PS-19902-013-001
 Sales Drawing SD-19164-031

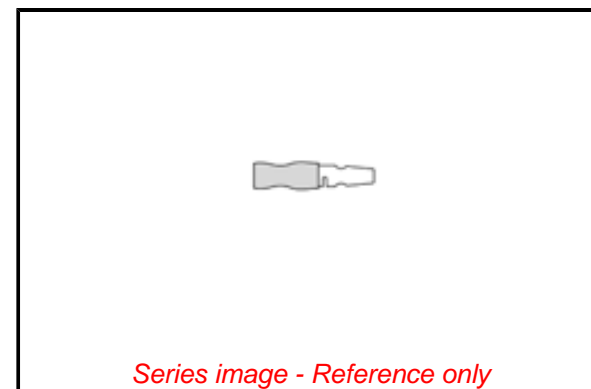

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
 ED/30/2017 (7 July
 2017)

Halogen-Free

Status

Low-Halogen

**Need more information on product
 environmental compliance?**

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any
 non-product compliance questions.

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

Search Parts in this Series

19164 Series