

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0190430001](#)
Status: **Active**
Overview: Standard Quick-Disconnect Terminals
Description: Double Male / Single Female Quick Disconnect Adapter, 6.35 x 0.81mm Tab Size, Non-Plated

Documents:

[Drawing \(PDF\)](#) [Product Specification PS-19902-013-001 \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Quick Disconnects
Series	19043
Crimp Quality Equipment	Yes
Insulated	No
MolexKits	Yes
Overview	Standard Quick-Disconnect Terminals
Product Name	Adapter
Type	Quick Disconnect
UPC	800755059496

Physical

Barrel Type	N/A
Gender	Dual
Glow-Wire Compliant	No
Insulation	None
Lock to Mating Part	None
Material - Metal	Brass
Material - Plating Mating	Unplated
Material - Plating Termination	Unplated
Net Weight	1.579/g
Orientation	Straight
Packaging Type	Bag
Tab Thickness	0.81mm
Tab Width	6.35mm
Termination Interface: Style	N/A
Wire Insulation Diameter	N/A
Wire Size AWG	N/A

Electrical

Voltage - Maximum	N/A
-------------------	-----

Solder Process Data


Lead-freeProcess Capability	N/A
-----------------------------	-----

Material Info

Engineering Number	MMFA
--------------------	------

Reference - Drawing Numbers

Product Specification	PS-19902-011-001, PS-19902-013-001
Sales Drawing	SD-19043-001

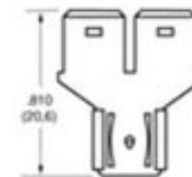

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/30/2017 (7 July
2017)

Halogen-Free

Status

Low-Halogen

**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[19043 Series](#)