

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** **0150151051**  
**Status:** **Active**  
**Overview:** Premo-Flex™ Cable Jumpers  
**Description:** 0.30mm Pitch Premo-Flex™ Etched Copper Polyimide Jumper, Same Side Contacts (Type A), 0.254m Cable Length, 0.12mm Cable Thickness, 51 Circuits

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Product Specification PS-15015-001-001 \(PDF\)](#)

**General**

Product Family	Cable
Series	<u>15015</u>
Crimp Quality Equipment	Yes
Overview	<u>Premo-Flex™ Cable Jumpers</u>
Product Name	Premo-Flex™ FFC Jumper
UPC	884982822832

**Physical**

Cable Length	0.254m
Circuits (Loaded)	51
Circuits (maximum)	51
Net Weight	1.000/g
Packaging Type	Bag
Pitch - Termination Interface	0.30mm
Temperature Range - Operating	-40°C to +105°C
Wire Size AWG	N/A
Wire/Cable Type	Flat Flex Cable


**Electrical**

Current - Maximum per Contact	0.2A
Voltage - Maximum	50V AC/DC

**Material Info**

**Reference - Drawing Numbers**

Product Specification	PS-15015-001-001
Sales Drawing	SD-15015-001

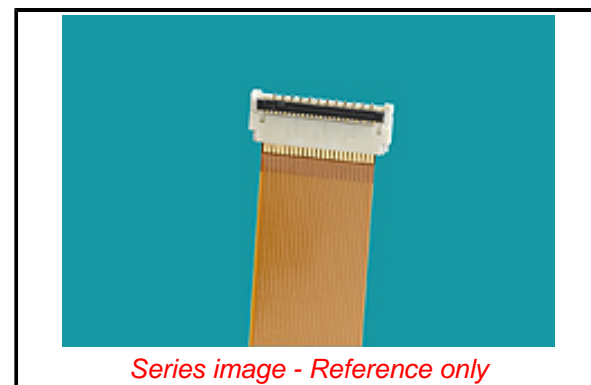

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Contained Per -  
ED/30/2017 (7 July 2017)

2,4-Di-tert-butyl-6-(5-chlorobenzotriazol-2-yl)p

**Halogen-Free**

**Status**

**Low-Halogen**

**Need more information on product environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

**Search Parts in this Series**

[15015 Series](#)

**Use With**

[502598](#) 0.30mm Pitch Easy-On™  
BackFlip™ Type FPC Connector