

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0150200065**
Status: **Active**
Overview: Premo-Flex™ Cable Jumpers
Description: 0.50mm Pitch Premo-Flex™ FFC Jumper, Same Side Contacts (Type A), 6 Circuits, 0.203m Cable Length, 0.27mm Cable Thickness, Gold (Au) Plating

Documents:

[Drawing \(PDF\)](#) [Packaging Specification PK-15020-001-001 \(PDF\)](#)
[Product Specification PS-15020-001-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family Cable
 Series 15020
 Comments Contacts on the same side, Type A
 Crimp Quality Equipment Yes
 Overview Premo-Flex™ Cable Jumpers
 Product Name Premo-Flex™ FFC Jumper
 UPC 884982175273

Physical

Cable Length 0.203m
 Circuits (Loaded) 6
 Circuits (maximum) 6
 Net Weight 0.401/g
 Packaging Type Bag
 Pitch - Termination Interface 0.50mm
 Temperature Range - Operating -40°C to +105°C
 Wire Size AWG N/A
 Wire/Cable Type Flat Flex Cable


Electrical

Current - Maximum per Contact 0.5A
 Voltage - Maximum 60V AC

Material Info

Reference - Drawing Numbers

Packaging Specification PK-15020-001-001
 Product Specification PS-15020-001-001
 Sales Drawing SD-15020-001

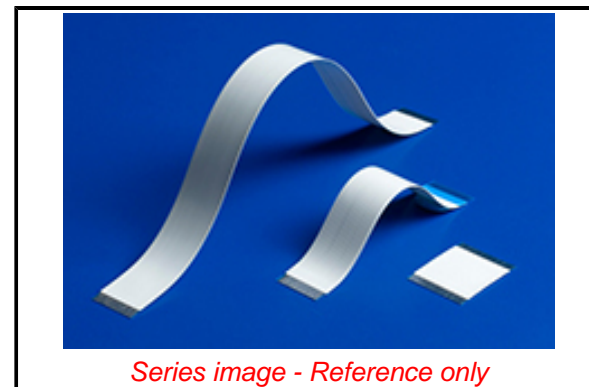

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
 ED/30/2017 (7 July
 2017)

Halogen-Free

Status

Not Low-Halogen

**Need more information on product
 environmental compliance?**

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any
 non-product compliance questions.

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

Search Parts in this Series

15020 Series

Use With

 Molex FFC – FPC connector. Be sure to
 match like plating.