

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1110401054](#)
Status: **Active**
Overview: [QSFP+ Interconnect Solution](#)
Description: QSFP+-to-QSFP+ Cable Assembly, 30 AWG, 0.50m Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Packaging Specification PK-111040-1054 \(PDF\)](#)

Agency Certification

UL E72548

General

Product Family Cable Assemblies
 Series [111040](#)
 Assembly Configuration Dual Ended Connectors
 Connector to Connector QSFP+-to-QSFP+
 Overview [QSFP+ Interconnect Solution](#)
 Product Name QSFP+
 UPC 883906967512

Physical

Cable Length 0.50m
 Circuits (Loaded) MSA
 Gender Plug
 Lock to Mating Part Yes
 Net Weight 65.200/g
 Packaging Type Bag
 Single Ended No
 Wire Size AWG 30
 Wire/Cable Type Round

Electrical


Impedance 100Ω

Material Info

Engineering Number 111050-1054

Reference - Drawing Numbers

Packaging Specification PK-111040-1054

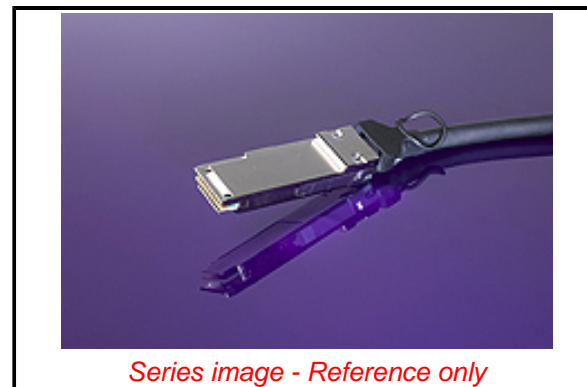

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Contained Per -
 ED/30/2017 (7 July
 2017)
 2,4-Di-tert-butyl-6-(5-
 chlorobenzotriazol-2-
 yl)p

Halogen-Free

Status

Not Low-Halogen

**Need more information on product
 environmental compliance?**

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any
 non-product compliance questions.

China ROHS	Green Image
ELV	Compliant
RoHS Phthalates	Not Contained

Search Parts in this Series

[111040](#) Series

Mates With

[75586](#) 38 Circuit iPass SMT Connector

Use With

[74750](#) , [74768](#) , [74769](#) EMI Cage