

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** **0190670025**  
**Status:** **Active**  
**Overview:** Solderless Terminals  
**Description:** NylaKrimp™ Funnel Entry Ring Tongue Terminal for 8 AWG Wire, Stud Size 5/16" (M8)

**Documents:**

[Drawing \(PDF\)](#) [Product Specification PS-19902-016-001 \(PDF\)](#)  
[Product Specification PS-19902-011-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Product Specification PS-19902-013-001 \(PDF\)](#)

**Agency Certification**

CSA LR18689  
 UL E32244

**General**

Product Family Ring and Spade Terminals  
 Series 19067  
 Crimp Quality Equipment Yes  
 Mil-Spec N/A  
 Overview Solderless Terminals  
 Product Name NylaKrimp™  
 Type Ring  
 UPC 800753065574

**Physical**

Barrel Type Closed - Brazed  
 Flammability 94V-2  
 Insulation Nylon (PA)  
 Material - Plating Mating Tin  
 Net Weight 3.836/g  
 Packaging Type Bag  
 Plating min - Mating 2.540µm  
 Plating min - Termination 2.540µm  
 Stud Size 5/16" (M8)  
 Termination Interface: Style Crimp or Compression  
 Wire Insulation Diameter 8.98mm max.  
 Wire Size AWG 8

**Solder Process Data**


Lead-freeProcess Capability N/A

**Material Info**

Engineering Number D-951-56

**Reference - Drawing Numbers**

Product Specification PS-19902-011-001, PS-19902-013-001,  
 PS-19902-016-001  
 Sales Drawing SD-19067-017

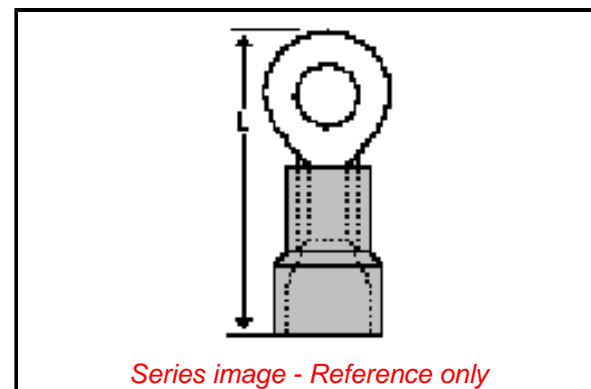

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
 ED/30/2017 (7 July  
 2017)

**Halogen-Free**

**Status**

**Not Low-Halogen**

**Need more information on product  
 environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
 Please visit the [Contact Us](#) section for any  
 non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

**Search Parts in this Series**

[19067 Series](#)