

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0673298020](#)  
**Status:** **Active**  
**Overview:** Consumer USB Products  
**Description:** Universal Serial Bus (USB) Shielded I/O Receptacle, Type A, Single Upright Right Angle, Solder Tail Length 2.00mm, 3.65mm Beveled Metal Pins, PCB Thickness 1.60mm, Gold (Au) Flash, Lead-Free

**Documents:**

[3D Model](#) [Packaging Specification PK-67329-001-001 \(PDF\)](#)  
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Product Specification PS-89485 \(PDF\)](#)

**Agency Certification**

UL E29179


**General**

Product Family I/O Connectors  
 Series [67329](#)  
 Application Wire-to-Board  
 Comments Standard Mount Type|Beveled Metal Pin Length: 3.65mm  
 Component Type Receptacle  
 Overview [Consumer USB Products](#)  
 Product Name USB 2.0  
 Type A  
 UPC 822350416900

**Physical**

Boot Color N/A  
 Circuits (Loaded) 4  
 Circuits (maximum) 4  
 Flammability 94V-0  
 Gender Receptacle  
 Lock to Mating Part Yes  
 Material - Plating Mating Gold  
 Material - Plating Termination Tin  
 Net Weight 1.937/g  
 Number of Rows 4  
 Orientation Upright  
 PC Tail Length 2.00mm  
 PCB Locator Yes  
 PCB Retention Yes  
 PCB Thickness - Recommended 1.60mm  
 Packaging Type Tray  
 Panel Mount No  
 Pitch - Mating Interface N/A  
 Pitch - Termination Interface 1.40mm  
 Plating min - Mating 0.102µm  
 Plating min - Termination 2.540µm  
 Polarized to Mating Part Yes  
 Polarized to PCB Yes  
 Ports 1  
 Surface Mount Compatible (SMC) Yes  
 Termination Interface: Style Through Hole  
 Waterproof / Dustproof No

**Electrical**

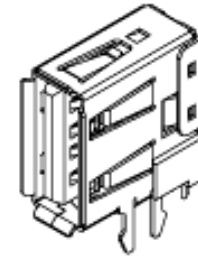

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per  
 -ED/01/2017 (12  
 January 2017)

**Halogen-Free**

**Status**

**Not Low-Halogen**

**Need more information on product environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
 Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[67329](#) Series

**Mates With**

USB Type A Plug

Current - Maximum per Contact	1.0A
Shield Type	Full Shield
Shielded	Yes

**Solder Process Data**

Lead-freeProcess Capability	N/A
-----------------------------	-----

**Material Info****Reference - Drawing Numbers**

Electrical Model Document	EE-67329-001
Packaging Specification	PK-67329-001-001
Product Specification	PS-89485
Sales Drawing	SD-67329-802

This document was generated on 06/20/2017

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**