

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0010013036](#)  
**Status:** **Active**  
**Overview:** SPOX™ Wire-to-Board Connectors  
**Description:** 5.08mm Pitch SPOX™ Crimp Terminal Housing, 3 Circuits

**Documents:**

[3D Model](#) [Product Specification PS-5197-001 \(PDF\)](#)  
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**

CSA LR19980  
 UL E29179

**General**

Product Family Crimp Housings  
 Series [5197](#)  
 Application Signal, Wire-to-Board  
 Overview [SPOX™ Wire-to-Board Connectors](#)  
 Product Name SPOX™  
 UPC 800754313124

**Physical**


Circuits (maximum) 3  
 Color - Resin Natural  
 Flammability 94V-2  
 Gender Receptacle  
 Glow-Wire Compliant No  
 Material - Resin Nylon  
 Net Weight 1151.200/mg  
 Number of Rows 1  
 Packaging Type Bag  
 Panel Mount No  
 Pitch - Mating Interface 5.08mm  
 Stackable No  
 Temperature Range - Operating -40°C to +105°C

**Material Info**

Engineering Number 5197-03

**Reference - Drawing Numbers**

Product Specification PS-5197-001  
 Sales Drawing SD-5197-N

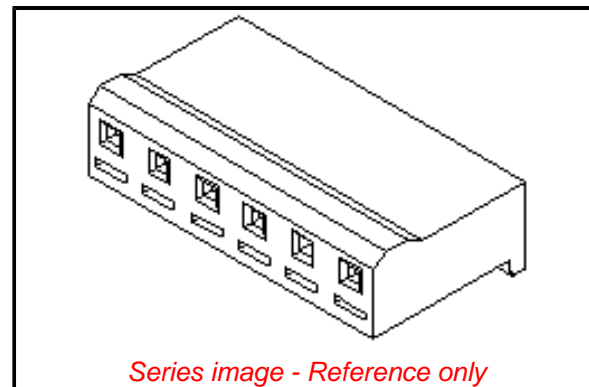

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**China RoHS**

**REACH SVHC**

Not Contained Per -  
 ED/30/2017 (7 July  
 2017)

**Halogen-Free**

**Status**

**Low-Halogen**

**Need more information on product  
 environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
 Please visit the [Contact Us](#) section for any  
 non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

**Search Parts in this Series**

[5197 Series](#)

**Mates With**

[5281](#) , [5282](#)

**Use With**

[5194](#) , [5225](#)

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**