

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0745470305](#)
Status: **Active**
Overview: [iPass™ Connector System](#)
Description: External iPass Mini Multi-Lane SAS X4 Cable Assembly, 26 Circuits, 26 AWG, 5.0m Length, Key 2, 4, 6

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Test Summary TS-74547-001 \(PDF\)](#)

Agency Certification

CSA LR64395
 UL E72548

General

Product Family Cable Assemblies
 Series [74547](#)
 Assembly Configuration Dual Ended Connectors
 Comments Universal Key, SAS
 Connector to Connector Mini SAS-to-Mini SAS
 Overview [iPass™ Connector System](#)
 Product Name iPass™, Mini Multi-Lane, SAS, X4
 UPC 822350284493

Physical

Cable Length 5.0m
 Circuits (Loaded) 26
 Gender Plug
 Lock to Mating Part Yes
 Material - Metal Stainless Steel
 Net Weight 783.180/g
 Packaging Type Bag
 Single Ended No
 Wire Insulation Diameter N/A
 Wire Size AWG 28
 Wire/Cable Type Parallel Pair


Electrical

Shield Type N/A
 Shielded No

Material Info

Reference - Drawing Numbers

Sales Drawing SD-74547-100
 Test Summary TS-74547-001

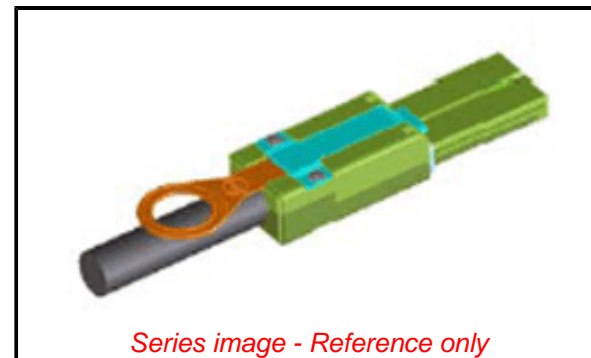

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
 ED/108/2014 (17 Dec
 2014)

Halogen-Free

Status

Not Low-Halogen

**Need more information on product
 environmental compliance?**

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any
 non-product compliance questions.

China ROHS Green Image
 ELV Not Relevant
 RoHS Phthalates Not Contained

Search Parts in this Series

[74547](#) Series

Mates With

[75586](#) iPass Receptacle. [74548](#) EMI
 Housing Assembly

Use With

[74735](#) X2 Transceiver. [74739](#) XPAK
 Transceiver. [74548](#) External iPass Mini
 Multi-Lane SAS Guide Frame