

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1110251200](#)
Status: **Active**
Overview: [CXP Interconnect System](#)
Description: iPass+™ High-Speed Channel (HSC) CXP Cable Assembly, 12X Quad Data Rate (QDR), 84 Circuits, 0.50m Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E72548

General

Product Family Cable Assemblies
 Series [111025](#)
 Assembly Configuration Dual Ended Connectors
 Comments Hot Pluggable, Pull to Release Style Latch
 Connector to Connector InfiniBand* 12x Both Ends, iPass-to-iPass
 Overview [CXP Interconnect System](#)
 Product Name InfiniBand*, iPass+™
 UPC 883906021276

Physical


Cable Length 0.50m
 Circuits (Loaded) 84
 Gender Male
 Lock to Mating Part Yes
 Material - Metal Zinc Alloy
 Material - Plating Mating Gold
 Net Weight 223.359/g
 Packaging Type Bag
 Single Ended No
 Wire/Cable Type Twin-ax

Electrical

Current - Maximum per Contact 0.5A
 Impedance 100Ω
 Voltage - Maximum 30V AC

Material Info

*InfiniBand is a trademark of the InfiniBand Trade Association

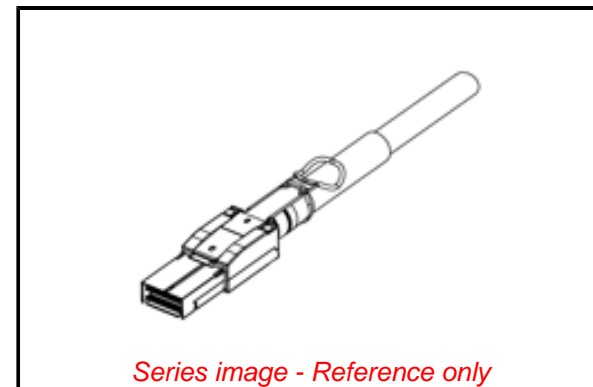

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
 ED/108/2014 (17 Dec
 2014)

Halogen-Free

Status

Not Low-Halogen

**Need more information on product
 environmental compliance?**

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any
 non-product compliance questions.

China ROHS Green Image
 ELV Not Relevant
 RoHS Phthalates Contained: BBP

Search Parts in this Series

[111025](#) Series

Mates With

[76105-0584](#) iPass™+ 84 Circuit Connector