

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0194340003**
Status: **Active**
Overview: MX150L™ Industrial Sealed Connector System
Description: MX150L™ Female Terminal for 10-12 AWG Wire

Documents:

Drawing (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification PS-19432-001-001 (PDF)	Product Literature (PDF)
Packaging Specification PK-19434-001 (PDF)	

Agency Certification

CSA	LR18689
UL	E152602

General

Product Family	Crimp Terminals
Series	<u>19434</u>
Application	Power
Comments	UL E152602
Crimp Quality Equipment	Yes
Overview	<u>MX150L™ Industrial Sealed Connector System</u>
Packaging Alternative	<u>19434-0001 (Reel)</u>
Product Literature Order No	987650-2181
Product Name	MX150L™
UPC	822350193153


Physical

Gender	Female
Material - Metal	Copper
Material - Plating Mating	Tin
Net Weight	0.844/g
Packaging Type	Bag
Wire Insulation Diameter	3.94mm-4.45mm
Wire Size AWG	10, 12
Wire Size mm²	N/A

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-19434-001
Product Specification	PS-19432-001-001
Sales Drawing	SD-19434-001

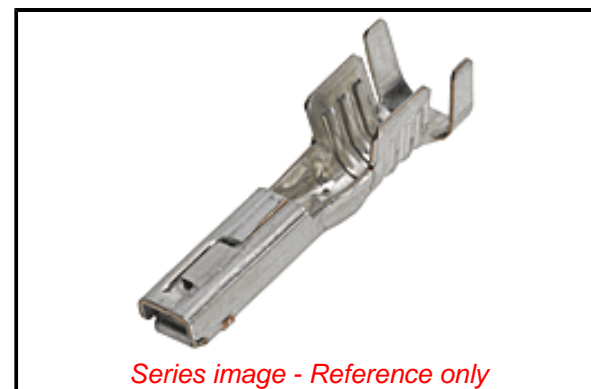

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/30/2017 (7 July
2017)

Halogen-Free

Status

Low-Halogen

**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

19434 Series

Mates With

19431 Male Terminal

Use With

19432 Female Receptacle

Application Tooling | FAQ

*Tooling specifications and manuals are
found by selecting the products below.
Crimp Height Specifications are then
contained in the Application Tooling
Specification document.*

Global

Description	Product #
Hand Crimp Tool for Crimp Terminals	<u>0638115300</u>

This document was generated on 08/03/2017

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION