

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0393800103](#)
Status: **Active**
Overview: Eurostyle™ Terminal Blocks
Description: 6.35mm Pitch Beau Eurostyle Fixed Mount PCB Terminal Block, Modular, 3 Circuits

Documents:

[3D Model](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Drawing \(PDF\)](#)

General

Product Family	Terminal Blocks
Series	39380
Application	N/A
Component Type	One Piece
Overview	Eurostyle™ Terminal Blocks
Product Name	Eurostyle™ Fixed Mount
Type	Euro Block
UPC	822348022984

Physical

Circuits (Loaded)	3
Color - Resin	Black
Entry Angle	Horizontal
Lock to Mating Part	None
Material - Resin	Nylon
Number of Rows	1
Orientation	Vertical
PC Tail Length	12.70mm
PCB Retention	None
PCB Thickness - Recommended	4.00mm
Panel Mount	No
Pitch - Mating Interface	6.35mm
Pitch - Termination Interface	6.35mm
Polarized to Mating Part	N/A
Shrouded	Fully
Stackable	Yes
Surface Mount Compatible (SMC)	No
Temperature Range - Operating	110°C
Wire Size AWG	10, 12, 14, 16, 18, 20, 22, 24, 26, 28, 30
Wire Size mm²	0.05-2.50

Electrical


Current - Maximum per Contact	30.0A
Voltage - Maximum	300V

Material Info

Engineering Number	MX-MSP0300S-0N
--------------------	----------------

Reference - Drawing Numbers

Sales Drawing	SD-39380-001
---------------	--------------

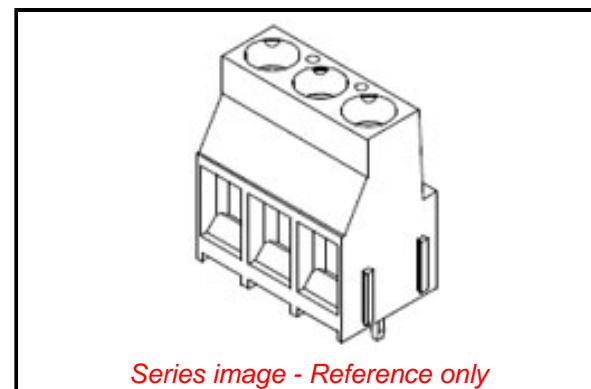

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

China RoHS

Search Parts in this Series

[39380 Series](#)