

Honeywell Sensing and Control

Search



11TL1-8

( Home : Products : Switches » MICRO SWITCH™ Toggle Switches » TL )

 
narrow your search

Products

- Controls Monitoring and Lighting (352)
- Machine Safety (1727)
- Sensors (5901)
- Switches (9775)
- Wireless (39)

Technology

- Control and Instrumentation (1052)
- Electromechanical (9301)
- Magnetic (541)
- Microstructure (1492)
- Thick Film (1409)



Actual product appearance may vary.

TL Series Toggle Switch, 1 pole, 2 position, Solder terminal, Standard Lever, Military Part Number MS27734-26

Sales & Service

Distributor Inventory

contacts

- Customer Service
- Technical Support
- Global Sales & Service
- View Site Demo
- Site Comments?

meet dr. larry

VIDEO - Dr. Larry Goldstein explains our newest and best technologies.



Meet Dr. Larry

my links

- Login to iCOM
- Login to Rep/AD Portal
- Login to Digital University

News Center

HONEYWELL ANNOUNCES ADDITION TO RELIALIGN™ RESIDENTIAL DOOR INTERLOCK SWITCHES THAT FEATURE RUGGED, PLASTIC HOUSING

HONEYWELL'S XYR6000 WIRELESS POSITION SENSOR ENABLES MONITORING IN HAZARDOUS AREAS AND REMOTE LOCATIONS

HONEYWELL RELEASES UNLIMITED POTENTIAL WITH NEW LIMITLESS™ WIRELESS SWITCHES

MICRO SWITCH Anniversary site

new products

New Wireless Products

Go farther. Work smarter. Explore new possibilities. Just by cutting the cord and making the switch.



Wireless Web Site WGLA and WPMM XYR6000™

find out more

white papers

- Wireless Switches Offer Unlimited Benefit
- Basic Switches Are Not Created Equal
- Applying Precision Switches
- Sensors for Medical Devices
- New Ways to Measure Torque
- Choosing Safety Switches
- Specifying Hour Meters


Need help?

Click here to contact us

Overview Specs Documentation Application Notes

Product Specifications

Circuitry/Operating action

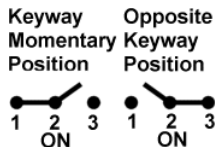

Product Type

MICRO SWITCH™ Toggle Switch

Ampere/Voltage Range (Resistive Load)

0.75 A at 115 Vdc; 0.5 A to 15 A at 0.5 Vdc to 28 Vdc; 0.5 A at 250 Vdc; 0.5 A to 10 A at 0.5 Vac to 7 Vac

Circuitry

SPDT

Action

2 position

Mounting

Bushing 15/32 in

Termination

Solder

MIL Spec. Number

MS27734-26

Lever Type

Standard

UL/CSA

L192: 10 A-125, 250, 277 Vac; 1/4 Hp-125 Vac; 1/2 Hp-250, 277 Vac; 3 A-125 Vac "L"

Comment

Single turret solder lug termination

Availability

Global

UNSPSC Code

30211908

UNSPSC Commodity

30211908 Toggle switches

Series Name

TL