

Honeywell Sensing and Control

Search



12TL1-2

(Home : Products : Switches » MICRO SWITCH™ Toggle Switches » TL)

narrow your search

Products

- Controls Monitoring and Lighting (286)
- Machine Safety (1727)
- Sensors (6158)
- Switches (9781)
- Wireless (45)

Technology

- Control and Instrumentation (890)
- Electromechanical (9303)
- Magnetic (538)
- Platinum thin film (56)
- Thick Film (1372)
- More...

new products

New Wireless Products

Go farther. Work smarter. Explore new possibilities. Just by cutting the cord and making the switch.



Wireless Web Site
WGLA and WPMM
XYR6000™

 
[find out more](#)

white papers

- Wireless Switches Offer Unlimited Benefit
- Basic Switches Are Not Created Equal
- Applying Precision Switches
- Sensors for Medical Devices
- New Ways to Measure Torque
- Choosing Safety Switches
- Specifying Hour Meters

Need help?

[Click here to contact us](#)



Actual product appearance may vary.

TL Series Toggle Switch, 2 pole, 2 position, Solder terminal, Standard Lever, Military Part Number MS27735-22


[Sales & Service](#)

[Distributor Inventory](#)

[Overview](#) [Specs](#) [Documentation](#) [Application Notes](#)

Product Specifications

Circuitry/Operating action

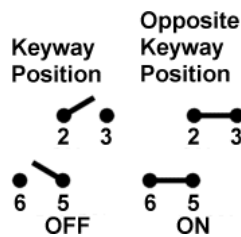

Product Type

MICRO SWITCH™ Toggle Switch

Ampere/Voltage Range (Resistive Load)

0.75 A at 115 Vdc, 0.5 A to 20 A at 0.5 Vdc to 28 Vdc, 0.5 A at 250 Vdc, 0.5 A to 15 A at 0.5 Vac to 277 Vac

Circuitry

DPST

Action

2 position

Mounting

Bushing 15/32 in

Termination

Solder

MIL Spec. Number

MS27735-22

Lever Type

Standard

UL/CSA

L191: 15 A-125, 250, 277 Vac; 1/2 Hp-125 Vac; 1 Hp-250, 277 Vac; 5 A-120 Vac "L"

Comment

Single turret solder lug termination

Availability

Global

UNSPSC Code

30211908

UNSPSC Commodity

30211908 Toggle switches

Series Name

TL

contacts

Customer Service
Technical Support
Global Sales & Service
View Site Demo
Site Comments?

meet dr. larry

VIDEO - Dr. Larry Goldstein explains our newest and best technologies.



Meet Dr. Larry

my links

[Login to iCOM](#)
[Login to Rep/AD Portal](#)
[Login to Digital University](#)

News Center

HONEYWELL INTRODUCES TRUSTABILITY® NSC SERIES, UNCOMPENSATED / UNAMPLIFIED BOARD MOUNT PRESSURE SENSORS

HONEYWELL EXPANDS ITS LIMITLESS™ PLATFORM WITH THE LAUNCH OF ITS GLOBALLY AVAILABLE INDUSTRIAL WIRELESS RECEIVER

HONEYWELL EXTENDS ITS TRUSTABILITY® PRESSURE SENSOR PRODUCT LINE WITH A SINGLE SIDE LIQUID MEDIA OPTION

MICRO SWITCH Anniversary site