

# Honeywell Sensing and Control

Search



**narrow your search**

**Products**


- Controls Monitoring and Lighting (354)
- Machine Safety (1726)
- Sensors (7016)
- Switches (9736)

**Technology**

- Control and Instrumentation (1063)
- Electromechanical (9297)
- Microstructure (2298)
- Optical/Infrared (1077)
- Thick Film (1764)
- More...

## 12TL1-8 MICRO SWITCH™ Toggle Switches

(Home : Products)

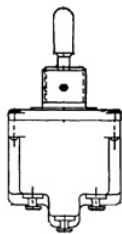

*Actual product appearance may vary.*

TL Series Toggle Switch, 2 pole, 2 position, Solder terminal, Standard Lever, Military Part Number MS27735-26

[Sales & Service](#)

[Distributor Inventory](#)


**Need Help?**

[Click here to contact us](#)

[Overview](#) [Specs](#) [Documentation](#) [Application Notes](#)

**Product Specifications**

Circuitry/Operating action

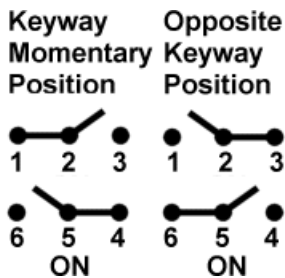

Product Type	MICRO SWITCH™ Toggle Switch
Ampere/Voltage Range (Resistive Load)	0.75 A at 115 Vdc, 0.5 A to 18 A at 0.5 Vdc to 28 Vdc, 0.5 A to 10 A at 0.5 Vac to 277 Vac, 0.5 A at 250 Vdc
Circuitry	DPDT
Action	2 position
Circuitry/Operating action	124948
Mounting	Bushing 15/32 in
Termination	Solder
MIL Spec. Number	MS27735-26
Lever Type	Standard
UL/CSA	L192: 10 A-125, 250, 277 Vac; 1/4 Hp-125 Vac; 1/2 Hp-250, 277 Vac; 3 A-125 Vac "L"
Comment	Single turret solder lug termination
Availability	Global
UNSPSC Code	30211908
UNSPSC Commodity	30211908 Toggle switches
Series Name	TL