
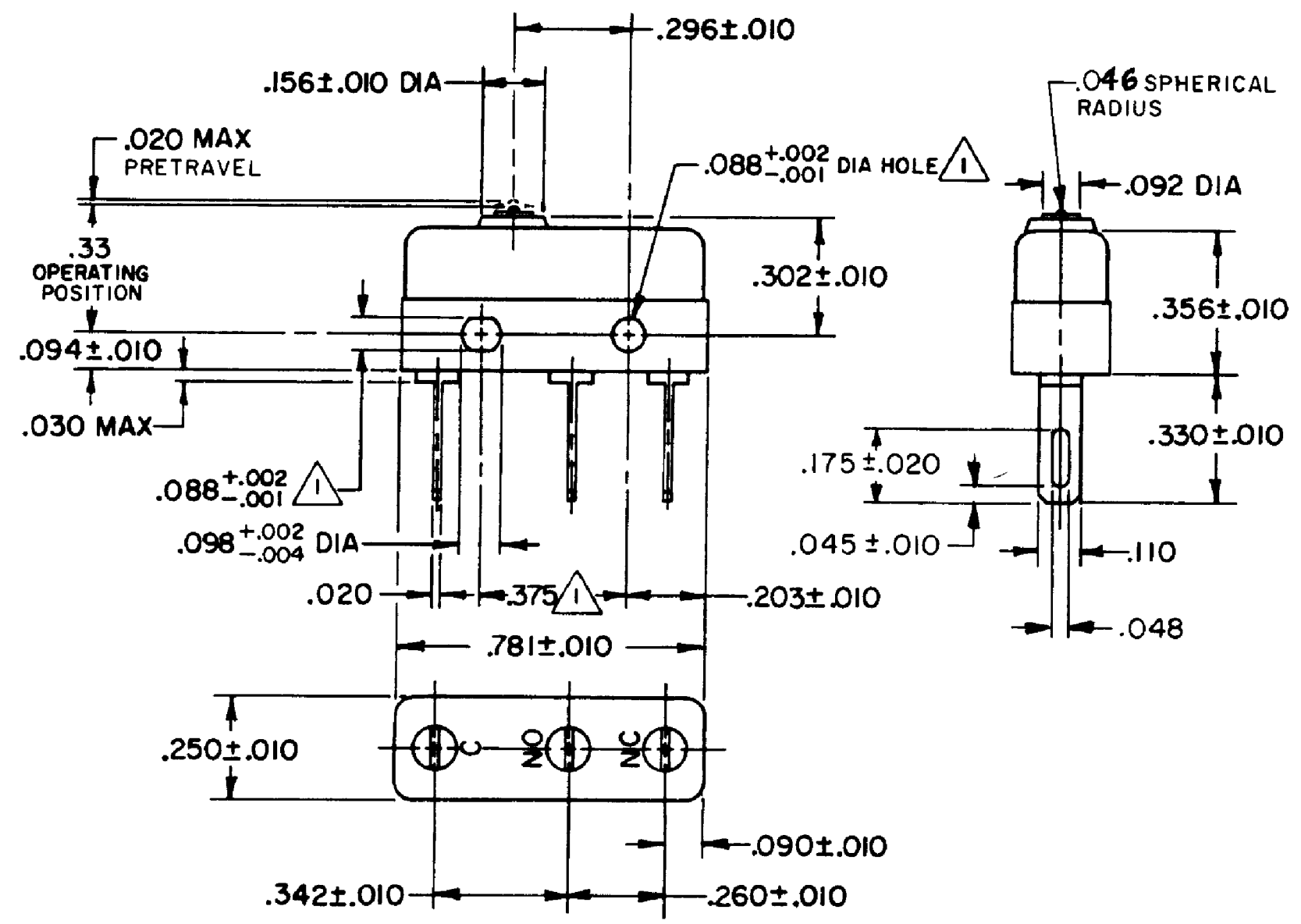


HONEYWELL PART NUMBER
11SM244-H4
PRODUCT CODE TWW4410

REV	DOCUMENT	CHANGED BY	CHECK
4	0093246	DJS 03OCT12	CMH

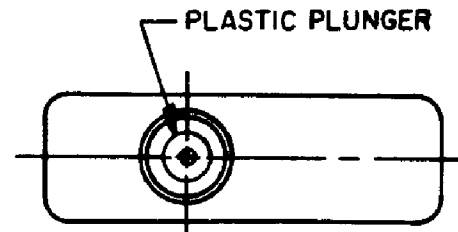

- NOTES**
- 1 MOUNTING HOLES WILL ACCEPT PINS OR SCREWS OF .087 MAX DIA ON .375 ± .002 CENTERS
 - 2 TERMINALS ARE PLATED FOR SOLDERING
 - 3 SWITCH WILL WITHSTAND TEMPERATURE OF 400°F

RELEASE NO.	PR - 11636
REPLACES	-

CHARACTERISTICS
OPERATING FORCE - - - - 3 - 5 OZ
RELEASE FORCE - - - - 1 OZ MIN
DIFFERENTIAL TRAVEL - - - .004 MAX
OVERTRAVEL - - - - - .005 MIN

ELECTRICAL DATA
KEMA, CE 5A, 250V ~ T85 1E4
UL 5A, 250 VAC 0.3A 125 VDC
CE
UL

DESIGN UNITS: INCH
TOLERANCES UNLESS NOTED:
NO PLACE X ±
ONE PLACE .X ±
TWO PLACE .XX ±
THREE PLACE .XXX ±
FOUR PLACE .XXXX ±
ANGLES ±
THIRD ANGLE PROJECTION

DRAWN	VK	27 NOV 07
CHECK	RJ	27 NOV 07
THIS DRAWING COVERS A PROPRIETARY ITEM AND IS THE PROPERTY OF HONEYWELL. THIS DRAWING IS NOT TO BE COPIED OR USED WITHOUT THE PERMISSION OF HONEYWELL.		
INTERPRET PER ANSI Y14.5M-1982 OTHER HONEYWELL ENGINEERING STANDARDS MAY APPLY		
RASTER		

Honeywell			
TITLE SWITCH - BASIC			
SIZE	TYPE	DRAWING NAME	REV
B	I	11SM244-H4	4
SCALE	NONE	WEIGHT .006 LB MAX	SHEET 1 OF 1