

Honeywell Sensing and Control

Search



2NT1-1L  
MICRO SWITCH™ Toggle Switches  
(Home : Products)

narrow your search

Products

- Controls Monitoring and Lighting (352)
- Machine Safety (1702)
- Sensors (6223)
- Switches (9750)
- Wireless (21)

Technology

- Control and Instrumentation (1052)
- Electromechanical (9301)
- Microstructure (1486)
- Optical/Infrared (1042)
- Thick Film (1764)
- More...



Actual product appearance may vary.

NT Series Toggle Switch, 2 pole, 3 position, Screw terminal, Locking Lever

Sales & Service

Distributor Inventory

contacts

- Customer Service
- Technical Support
- Global Sales & Service
- View Site Demo
- Site Comments?

meet dr. larry

VIDEO - Dr. Larry Goldstein explains our newest and best technologies.



Meet Dr. Larry

my links

- Login to iCOM
- Login as Rep/AD
- Login as Guest
- Login to Digital University

new products

New Wireless Products

Go farther. Work smarter. Explore new possibilities. Just by cutting the cord and making the switch.



Wireless Web Site  
WGLA and WPMM  
XYR6000™

find out more

white papers

- Wireless Switches Offer Unlimited Benefit
- Basic Switches Are Not Created Equal
- Applying Precision Switches
- Sensors for Medical Devices
- New Ways to Measure Torque
- Choosing Safety Switches
- Specifying Hour Meters


Need help?

Click here to contact us

Overview Specs Documentation Application Notes

Product Specifications

Circuitry/Operating action

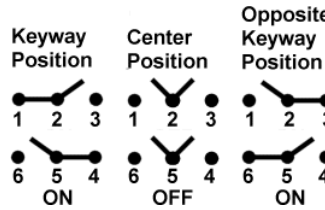

Product Type  
Lever Lock



Locked out of extreme position (Keyway side)

Ampere/Voltage Range (Resistive Load)	0.5 A to 15 A at 0.5 Vac to 277 Vac, 0.5 A at 250 Vdc, 0.75 A at 115 Vdc, 0.5 A to 20 A at 0.5 Vdc to 28 Vdc
Circuitry	DPDT
Action	3 position
Mounting	Bushing 15/32 in
Termination	Screw
Lever Type	Locking
UL/CSA	L191: 15 A-125, 250, 277 Vac; 1/2 Hp-125 Vac; 1 Hp-250, 277 Vac; 5 A-120 Vac "L"
Comment	Thermoplastic case
Availability	Global
UNSPSC Code	30211908
UNSPSC Commodity	30211908 Toggle switches
Series Name	NT

News Center

HONEYWELL ANNOUNCES ADDITION TO RELIALIGN™ RESIDENTIAL DOOR INTERLOCK SWITCHES THAT FEATURE RUGGED, PLASTIC HOUSING

HONEYWELL RELEASES UNLIMITED POTENTIAL WITH NEW LIMITLESS™ WIRELESS SWITCHES

HONEYWELL'S XYR6000 WIRELESS POSITION SENSOR ENABLES MONITORING IN HAZARDOUS AREAS AND REMOTE LOCATIONS

MICRO SWITCH Anniversary site