

HONEYWELL

343P200

See full Datasheet below...

onlinecomponents.com

THE ONLINE DISTRIBUTOR OF ELECTRONIC COMPONENTS

BUY NOW



MASTERTM
ELECTRONICS

BUY NOW

masterelectronics.com & onlinecomponents.com
are **authorized** e-commerce distributors
of electronic components.




Home > Products > Trimmers > 343 > Product Page

Order Product and Get Support

- U.S. Authorized Distributors
- Global Sales & Service
- N. American Sales Reps
- Distributor Inventory
- Technical Assistance
- White Papers
- Literature Request
- Test and Measurement Catalog
- RoHS Product List
- Customer Feedback

343P200

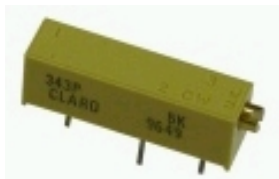

Actual product appearance may vary.

343 Series Trimmer, 200 Ohm, 0.75 W, 20 Turns, Rectangular Body, Horizontal Shaft

Features

- 20-turns
- 0.75 Watt
- Cermet element
- Low cost
- Low profile - only 6.35 mm (1/4 in) high brush contact and unique "T" slider block design assure CRV of 3 % or 3 Ohms contact idles at stops

Potential Applications

- Voltage divider circuits
- Telecommunications

Description

The 343 Series is a low profile, 19.05 mm (3/4 in.) rectangular, multturn trimmer. Made in accordance to MIL-R-22097 standards, the 343 is sealed for cleaning in common solvents.

Supporting Documentation

[▶ Dimensions](#)

Product Specifications	
Product Type	Trimmer
Watts	0.75 W
Turns	20
Element Type	Cermet
Resistance Value	200 Ohm
Resistance Tolerance	± 10 %
Temperature Coefficient	± 100 ppm/ °C
Body	19,05 mm [0.75 in] rectangular
Shaft Location	Horizontal
Rotational Life	200 cycles
Series Name	343
Availability	Global
UNSPSC Code	4111363300
UNSPSC Commodity	4111363300 Potentiometers

My Links

- [Login to iCOM](#)
- [Login as Rep/AD](#)
- [Login as Guest](#)
- [Login to Digital University](#)

Keyword Search

Search for product and support information.

All Sensing and Control

Product Search

Part number search:

Use (*) to expand search

[Specification Search](#)