


**80438 (/sensing.honeywell.com/product-page?pr\_id=)**

( [Home \(/\)](#) : [Products \(/products\)](#) : [Controls and Monitoring](#) : [Controls](#) : [Hobbs Shifter](#) )

Distributor Inventory

Input part number for stock availability

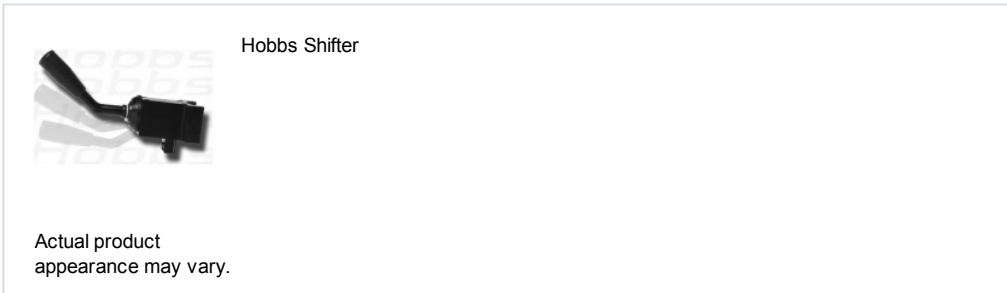

[Sales & Service](#)

[Distributor Inventory](#)

[Overview](#)

[Specs](#)

[Documentation](#)

**Product Specifications**

Product Type	Shifter
Mounting	Left or right
Column Size	38 mm [1.5 in] and 45 mm [1.77 in]
Neutral LocI	Yes
Speeds	F/N/R
Horn	No
Electrical Connection	Integral Packard
Operating Voltage	3 Vdc to 32 Vdc
Solenoid Load with Arc Suppression	2 A @ 12.8 Vdc
Sealing	IP67
Cycle Life (Lever)	3000000
Availability	Global
Comment	Shifter
Series Name	Hobbs Shifter

**Narrow Your Search**

**Modify Your Search**

**Products**

Select Option

**Technology**

Select Option

**Industries Served**

Select Option

FEEDBACK

CHAT

**Product Search**

Product Type:  ▼

Industry:  ▼

Search Term:

- New Products Only
- Entire Product Catalog

**Search**

[My Links](#)

[Literature and Media](#)


[Contacts](#)

[eCOM Login \(/index.php?ci\\_id=50629&la\\_id=1\)](/index.php?ci_id=50629&la_id=1)  
[Request Access to eCOM \(/ecom-access-request\)](/ecom-access-request)  
[Rep/AD Portal Login \(/index.php?ci\\_id=50606&la\\_id=1\)](/index.php?ci_id=50606&la_id=1)  
[Rep/AD Portal Access Request \(/index.php?ci\\_id=50630&la\\_id=1\)](/index.php?ci_id=50630&la_id=1)  
[Sample Request \(/samplerequest\)](/samplerequest)  
[Digital U - HWL Learning Hub Login \(/index.php?ci\\_id=50607&la\\_id=1\)](/index.php?ci_id=50607&la_id=1)

[Data Sheets \(/white-paper-and-technical-data-sheets-library2\)](/white-paper-and-technical-data-sheets-library2)  
[Videos \(/videos\)](/videos)  
[Literature \(/literature\)](/literature)  
[Literature Request \(/index.php?ci\\_id=50636&la\\_id=1\)](/index.php?ci_id=50636&la_id=1)  
[White Papers \(/whitepapers\)](/whitepapers)  
[Application Notes \(/application-notes\)](/application-notes)  
[Application Demos \(/index.php?ci\\_id=141383&la\\_id=1\)](/index.php?ci_id=141383&la_id=1)  
[CAD Renderings \(/cad-renderings\)](/cad-renderings)

[Customer Service \(/index.php?ci\\_id=50608&la\\_id=1\)](/index.php?ci_id=50608&la_id=1)  
[Technical Support \(/index.php?ci\\_id=50609&la\\_id=1\)](/index.php?ci_id=50609&la_id=1)  
[Global Sales & Service \(/index.php?ci\\_id=50610&la\\_id=1\)](/index.php?ci_id=50610&la_id=1)

[Limitless Microsite \(/index.php?ci\\_id=50631&la\\_id=1\)](/index.php?ci_id=50631&la_id=1)

 <https://www.youtube.com/user/SensingAndControl>  
[Supplier Microsite \(/index.php?ci\\_id=44887&la\\_id=1\)](/index.php?ci_id=44887&la_id=1)

[\(/contact\)](#)

[\(/contact\)](#) [\(/contact\)](#)

[Terms & Conditions \(/terms & conditions\)](/terms&conditions)

[Privacy Statement \(/index.php?ci\\_id=2589&la\\_id=1\)](/index.php?ci_id=2589&la_id=1)

[Site Map \(/sitemap\)](/sitemap)

FEEDBACK

CHAT