




12TW8-3D

(Home : Products : Switches : MICRO SWITCH™ Toggle Switches : TW)

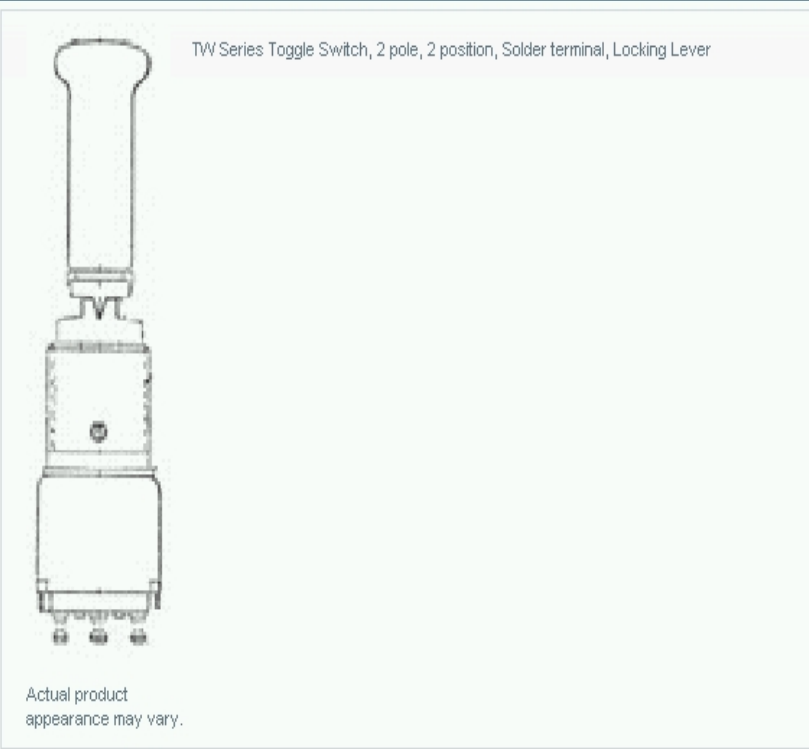

[Sales & Service](#) [Distributor Inventory](#)

[Overview](#) | [Specs](#) | [Documentation](#)

Description

MICRO SWITCH™ miniature toggle switches in two bushing sizes. Molded-in terminals are plated for soldering. Momentary and maintained circuitry closures available. Special on-on-on circuitries are also available. Pull-to-unlock levers prevent accidental operation.

Features

- Save space and weight
- SPDT and DPDT circuitry
- Temperature range: -85DF to +160DF (-65DC to +71DC)
- Sealed bushing versions
- Choice of 1/8 in. or 15/32 in. bushing
- Color tab available on 15/32 in. bushing
- UL recognized

Potential Applications

- Industrial machinery and equipment
- Military and commercial aviation
- Construction equipment
- Test instruments
- Agricultural machinery
- Process control
- Medical instrumentation

Product Search

Product Type:

New Products Only

Industry:

Entire Product Catalog

Search Term:

Search

[Distributor Inventory](#)

Input part number for stock availability

Narrow Your Search

Modify Your Search

Products

Select Option

Technology

Select Option

Industries Served

Select Option

My Links

- [eCOM Login](#)
- [Request Access to eCOM](#)
- [Rep/AD Portal Login](#)
- [Rep/AD Portal Access Request](#)
- [Sample Request](#)
- [Digital U - HWL Learning Hub Login](#)
- [Limitless Microsite](#)
- [Supplier Microsite](#)

Literature and Media

- [Data Sheets](#)
- [Videos](#)
- [Literature](#)
- [Literature Request](#)
- [White Papers](#)
- [Application Notes](#)
- [Application Demos](#)
- [CAD Renderings](#)

Contacts

- [Customer Service](#)
- [Technical Support](#)
- [Global Sales & Service](#)