




Product News 2015

NEUTRIK®




Horizontal PCB

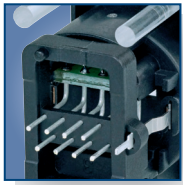

Vertical PCB with lightpipes



Locking release tab

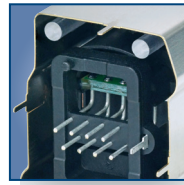

Shielded Version



etherCON CAT5e PCB Receptacle

NEW



NE8FAH-C5



NE8FBH-C5-LED



NE8FBV-C5-LED



NE8FBV-C5-LED-S

- Space saving A or B type receptacles - horizontal or vertical PCB design available
- Vertical PCB design at 24 mm distance to front panel – fits the widely accepted industry standard dimension for XLRs, 1/4" jacks etc.
- PoE+ compliant according to 802.3at Type2
- CAT5e performance according to ISO /IEC 11801 and TIA /EIA 568-C.2
- Shielded or non-shielded versions available
- Two types of light pipes available to accommodate through hole LEDs or SMD-LEDs
- Accommodates rugged etherCON NE8MC* cable carriers or any standard RJ45 plug

Ordering Information

NE8FAH-C5	etherCON A type horizontal PCB CAT5e
NE8FBH-C5	etherCON B type horizontal PCB CAT5e
NE8FBH-C5-S	etherCON B type horizontal PCB CAT5e with shielding
NE8FBH-C5-LED	etherCON B type horizontal PCB CAT5e through hole LED
NE8FBH-C5-LED1	etherCON B type horizontal PCB CAT5e SMD LED
NE8FBH-C5-LED-S	etherCON B type horizontal PCB CAT5e through hole LED with shielding
NE8FBH-C5-LED1-S	etherCON B type horizontal PCB CAT5e SMD LED with shielding
NE8FAV-C5	etherCON A type vertical PCB CAT5e
NE8FBV-C5	etherCON B type vertical PCB CAT5e
NE8FBV-C5-S	etherCON B type vertical PCB CAT5e with shielding
NE8FBV-C5-LED	etherCON B type vertical PCB CAT5e through hole LED
NE8FBV-C5-LED1	etherCON B type vertical PCB CAT5e SMD LED
NE8FBV-C5-LED-S	etherCON B type vertical PCB CAT5e through hole LED with shielding
NE8FBV-C5-LED1-S	etherCON B type vertical PCB CAT5e SMD LED with shielding



Rugged diecast shell



Feedthrough



IDC Version



IP Protected



etherCON CAT6A Series

NEW



NE8MX6



NE8FDX-P6



NE8FDX-Y6-W

- Ruggedized connector range with CAT6A component compliance according to ISO /IEC 11801 and TIA /EIA 568-C.2
- Cable connector suitable for a cable diameter range of 7 mm to 9.5 mm
- D-size chassis connector for IDC self-termination or as feedthrough adapter
- IP65 protected version available
- PoE+ compliant according to 802.3at Type2
- Rugged latch lock system million fold proven
- Downwards compatible with the existing etherCON CAT5 range, cable as well as chassis connectors

Ordering Information

NE8MX6	etherCON cable connector Cat6A, nickel plating
NE8MX6-B	etherCON cable connector Cat6A, black plating
NE8FDX-P6	etherCON chassis C6A shielded feedthrough, nickel plating
NE8FDX-P6-B	etherCON chassis C6A shielded feedthrough, black plating
NE8FDX-Y6	etherCON chassis C6A shielded IDC, nickel plating
NE8FDX-Y6-B	etherCON chassis C6A shielded IDC, black plating
NE8FDX-P6-W	etherCON chassis C6A shielded feedthrough, with rubber sealing, IP65
NE8FDX-Y6-W	etherCON chassis C6A shielded IDC, with rubber sealing, IP65

Accessories

HX-CAT6A	Parallel press tool CAT6A
----------	---------------------------




Locking release tab



Rear side

Availability
June 2015

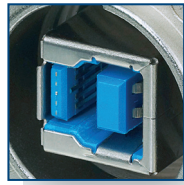

USB 3.0 Type B




Rugged housing

Availability
May 2015

etherCON feedthrough

NEW

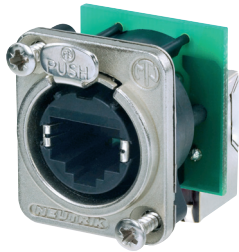

NE8FDP-R

- Rugged D-size feedthrough
- Rear end RJ45 right angle port
- CAT5e performance

USB 3.0 Adapter

NEW



NAUSB3



NAUSB3-B

- Rugged USB 3.0 feedthrough adapter
- Standardized D-shape housing
- Reversible insert offering type A or B on front or rear end
- Optional screen to chassis grounding
- Nickel and black chrome plating available

Ordering Information etherCON feedthrough

NE8FDP-R	etherCON chassis right-angle feedthrough, nickel plating
NE8FDP-R-B	etherCON chassis right-angle feedthrough, black plating

Ordering Information USB


NAUSB3	USB 3.0 type A – type B feedthrough adapter, nickel
NAUSB3-B	USB 3.0 type A – type B feedthrough adapter, black chrome



Nickel or black chrome plating



D-shape metal housing

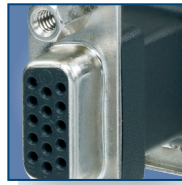

9 pole or 15 pole available

Availability
March 2015

D - S U B



NADB9FF



NADB9MF-B

- D-SUB feedthrough adapter
- Optimized ground connection
- Standardized D-shape housing
- 9 pole and 15 pole versions available
- "Male – Female" and "Female – Female" versions available
- Nickel and black chrome plating available

Ordering Information

NADB9MF	9 pole D-SUB feedthrough male-female, D-shape nickel housing
NADB9MF-B	9 pole D-SUB feedthrough male-female, D-shape black chrome housing
NADB9FF	9 pole D-SUB feedthrough female-female, D-shape nickel housing
NADB9FF-B	9 pole D-SUB feedthrough female-female, D-shape black chrome housing
NADB15MF	15 pole D-SUB feedthrough male-female, D-shape nickel housing
NADB15MF-B	15 pole D-SUB feedthrough male-female, D-shape black chrome housing
NADB15FF	15 pole D-SUB feedthrough female-female, D-shape nickel housing
NADB15FF-B	15 pole D-SUB feedthrough female-female, D-shape black chrome housing

Liechtenstein (Headquarters)

NEUTRIK AG, Im alten Riet 143, 9494 Schaan
T +423 237 24 24, F +423 232 53 93, neutrik@neutrik.com

Germany / Netherlands / Denmark / Austria

Neutrik Vertriebs GmbH, Felix-Wankel-Strasse 1, 85221 Dachau, Germany
T +49 8131 28 08 90, info@neutrik.de

Great Britain

Neutrik (UK) Ltd., Westridge Business Park, Cothey Way
Ryde, Isle of Wight PO33 1 QT
T +44 1983 811 441, sales@neutrik.co.uk

France

Neutrik France SARL, Rue du Parchamp 13, 92100 Boulogne-Billancourt
T +33 1 41 31 67 50, info@neutrik.fr

USA

Neutrik USA Inc., 4115 Taggart Creek Road, Charlotte, North Carolina, 28208
T +1 704 972 30 50, info@neutrikusa.com

Japan

Neutrik Limited, Yusen-Higashinibashi-Ekimaie Bldg., 3-7-19
Higashinibashi, Chuo-ku, Tokyo 103
T +81 3 3663 47 33, mail@neutrik.co.jp

Hong Kong

Neutrik Hong Kong LTD., Suite 18, 7th Floor Shatin Galleria
Fotan, Shatin
T +852 2687 6055, neutrik@neutrik.com.hk

China

Ningbo Neutrik Trading Co., Ltd., Shiqi Street, Yinxian Road West
Fengjia Villiage, Yinzhou Area, Ningbo, Zhejiang, 315153
T +86 574 88250488 800, neutrik@neutrik.com.cn

India

Neutrik India Pvt. Ltd., Level 3, Neo Vikram, New Link Road,
Above Audi Show Room, Andheri West, Mumbai, 400058
T +91 982 05 43 424, anklesaria@neutrik.com


Associated companies

Contrik AG

Steinackerstrasse 35, 8902 Urdorf, Switzerland
T +41 44 736 50 10, contrik@contrik.ch

H. Adam GmbH

Felix-Wankel-Straße 1, 85221 Dachau, Germany
T +49 08131 28 08-0, info@adam-gmbh.de

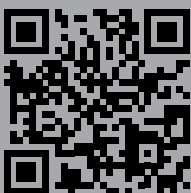

www.neutrik.com

2015/02



NEUTRIK[®]
SETTING STANDARDS SINCE 1975