


CMR SERIES - METAL RIGHT ANGLE COVER ULTRA LOW & LOW PROFILE (ULP/LP)

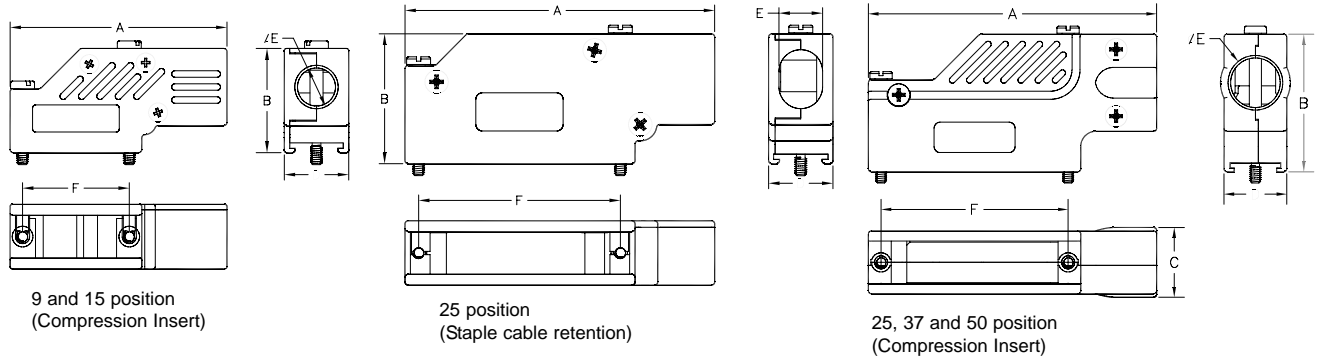

FEATURES:

- Ultra-Low profile design allows for use in applications where space is restricted.
- Tapped through-holes ensure easy and rapid assembly of cover for lower labor costs.
- Nortech™ “one-size-fits-all” Compression Insert System reduces connector cover inventory and provides excellent strain relief.
- Accommodates a wide range of O. D.'s.
- Available in sizes 9, 15, 25 and 37.

SPECIFICATIONS:

- Cover Material: Die-Cast Zinc.
- Plating: Nickel over Copper under-plate.
- Compression Insert: Black Thermoplastic UL94 (Compression Insert Versions Only)
- Assembly Hardware: #4-40 UNC Captive Screws - Ni Plated Steel (9 through 37 position)
- #2-56 UNC Machine Screws - Ni Plated Steel (9 & 15 position)
- #4-40 UNC Machine Screws - Bright Zinc Finish (25, 37 & 50 position).
- Staple: Steel - Bright Zinc Finish (Staple Version Only).

CMR SERIES – METAL RIGHT ANGLE (ULP/LP) - DIMENSIONS								
		PART NUMBERS	INCHES [MM]					
		NoLogo	A	B	C	D	E	F
9 Position	Bulk	NA30E900000	2.000	0.960	-----	0.594	0.400	0.984
	Packaged	N30E900000	[50.80]	[24.38]	-----	[15.08]	[10.10]	[25.00]
15 Position	Bulk	NA30E910000	2.336	0.960	-----	0.600	0.400	1.310
	Packaged	N30E910000	[59.33]	[24.38]	-----	[15.24]	[10.10]	[33.27]
25 Position	Bulk	NA30E920000	2.850	1.360	0.690	0.620	0.540	1.850
	Packaged	N30E920000	[72.39]	[34.54]	[17.52]	[15.75]	[13.72]	[47.00]
25 Position (Staple)	Bulk	NA30E950000	2.840	1.190	-----	0.590	0.400	1.850
	Packaged	N30E950000	[72.14]	[30.22]	-----	[14.99]	[10.16]	[47.00]
37 Position	Bulk	NA30E930000L	3.530	1.610	0.883	0.620	0.726	2.500
	Packaged	N30E930000L	[89.66]	[40.89]	[22.43]	[15.75]	[18.44]	[63.50]
50 Position	Bulk	NA30E940000L	3.420	1.610	0.880	0.710	0.726	2.406
	Packaged	N30E940000L	[86.87]	[40.89]	[22.35]	[18.03]	[18.44]	[61.11]