


PICO® Fuse Equivalent – 2.4 x 7mm Epoxy Coated Axial Lead

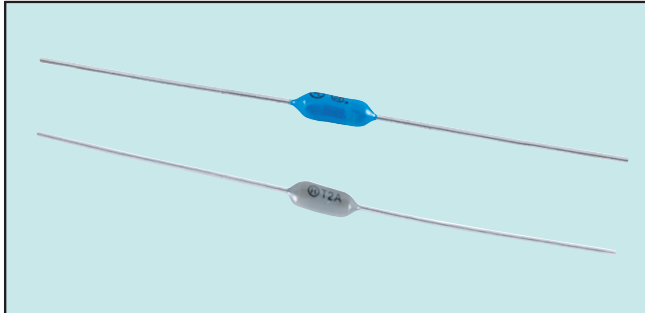


Features

- Available in Fast Acting and Slow Blow Types
- RoHS Compliant



F-09

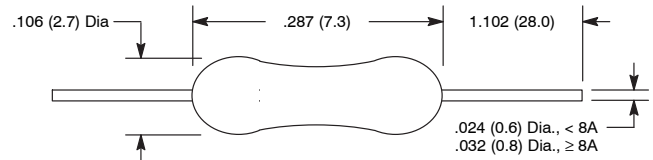

Specifications

Rated Voltage: 125V

Breaking Capacity:

Fast Acting:

125V, 50A (250mA – 3A); 125V, 30A (3.5A – 10A)

Slow Blow:

125V, 30A (375mA – 7A)

Time Current Characteristics:

% of Ampere Rating	Opening Time	
	Fast Acting	Slow Blow
100%	4 hours min.	4 hours min.
200%	20 seconds max.	60 seconds max.
300%	–	0.2 – 3.0 seconds
800%	–	0.02 – 0.1 seconds

Ordering Information:

NTE Type No.		Rated Current	Diag No.
Fast Acting	Slow Blow		
74-MF250MA		250mA	F-09
74-MF375MA	74-MS375MA	375mA	F-09
74-MF500MA	74-MS500MA	500mA	F-09
74-MF750MA	74-MS750MA	750mA	F-09
74-MF1A	74-MS1A	1.0A	F-09
74-MF1.5A	74-MS1.5A	1.5A	F-09
74-MF2A	74-MS2A	2.0A	F-09
74-MF2.5A	74-MS2.5A	2.5A	F-09
74-MF3A	74-MS3A	3.0A	F-09
74-MF3.5A	74-MS3.5A	3.5A	F-09
74-MF4A	74-MS4A	4.0A	F-09
74-MF5A	74-MS5A	5.0A	F-09
74-MF7A	74-MS7A	7.0A	F-09
74-MF10A		10A	F-09

NOTE: All fuses are CSA approved. Fast Acting fuse are UL listed up to 3A and UL recognized from 3.5A to 10A. Slow Blow fuses are UL recognize ONLY.