

# ProVision<sup>®</sup>


THE ULTIMATE INSPECTION TOOL

**For diagnosis and exploration!**

Available  
in 5 Cable  
Lengths  
up to 96"



**Inspects  
impossible-to-reach  
places!**

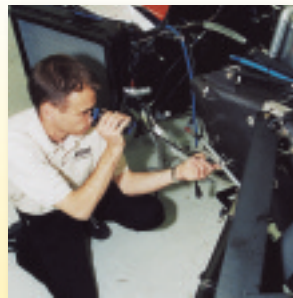

## ProVision Fiber Optic Inspection Scope & Accessories

### Perfect for:

- Mechanics
- Electricians
- Plumbers
- Exterminators
- HVAC Repair
- Welders
- Carpenters
- Home Owners
- Home Theatre Installers
- Home Inspectors
- Law Enforcement
- Insurance Adjusters
- Marine Industry
- Locksmiths

# ProVision<sup>®</sup>

"See-It, Fix-It!"<sup>(tm)</sup>

## THE ULTIMATE INSPECTION TOOL

The ProVision<sup>™</sup> line consists of a revolutionary variety of inspection tools that allows you to see into inaccessible places. It offers the same high performance and results as borescopes costing 10 times as much!

ProVision<sup>™</sup> will pay for itself over and over again in reduced labor costs. The amount of time you will **save troubleshooting** and problem-solving will make you **more productive and profitable** than ever before!



### Shaft diameters

2 sizes available



0.4"/10.5mm



0.23"/5.8mm

Illustrations are actual size

### Features & benefits

- Cable will reach deep into **walls, drains, vents, engine blocks, etc.**
- **Powerful halogen lamp** illuminates dark locations for clear viewing
- **"Obedient" cable** maintains its fixed position until readjusted
- **Flexible, omni-directional cable** bends in every direction to allow precise viewing
- **Pressure activated light switch** is conveniently located but cannot be accidentally left "on"
- **Integrated focus ring** for smooth, continuous focusing
- **Ergonomically designed**, non-slip handle fits comfortably in one hand

**PV1** Offers the same results as borescopes costing **10 times as much!**



Based on **innovative fiber optic technology**, ProVision's flexible cable fits into holes as small as 1/4" in diameter. **Designed for up close focusing in tight places**, the high resolution lens provides a clear image of objects as close as 3/4" away while providing a wide 40° field of view.

#### PV1 Standard Scope & Hard Case (no accessories)

64-PV100	18", 10.5mm Obedient Shaft
64-PV618	18", 5.8mm Non-obedient Shaft
64-PV300	36", 10.5mm Obedient Shaft
64-PV636	36", 5.8mm Non-obedient Shaft
64-PV300E	36", SS Shaft 7400 Pixels w/High Brightness LEDs

#### PV1 Long Scope & Square Case (no accessories)

64-PV480	48", 10.5mm Obedient Shaft
64-PV720	72", 10.5mm Obedient Shaft
64-PV960	96", 10.5mm Obedient Shaft

#### PV1 Scope & Kit Packages Scope w/ Mirror, Magnet, Bulb & Hard Case

64-PVM100	18", 10.5mm Obedient Shaft w/64-PVKM45 kit
64-PVM618	18", 5.8mm Non-obedient Shaft w/64-PVKM45M kit
64-PVM300	36", 10.5mm Obedient Shaft w/64-PVKM45 kit
64-PVM636	36", 5.8mm Non-obedient Shaft w/64-PVKM45M kit
64-PVM480	48", 10.5 Obedient Shaft w/64-PVKM45 kit
64-PVM720	72", 10.5mm Obedient Shaft w/64-PVKM45 kit
64-PVM960	96", 10.5mm Obedient Shaft w/64-PVKM45 kit

NOTE: All PV1 series are 6,000 pixel resolution

# PV2

The next generation of affordable inspection tools!



## Now with 7400 pixels!

PV2 Series	Scope & Hard Case (no accessories)
64-PV2100	18", PV2 Series 7400 Pixels w// Obedient Shaft
64-PV2618	18", PV2 Series 7400 Pixels w/ Non-Obedient Shaft
64-PV2300	36", PV2 Series 7400 Pixels w/ Obedient Shaft
64-PV2636	36", PV2 Series 7400 Pixels w/ Non-Obedient Shaft

- Higher resolution fiber optics
- True one-handed operation
- Stay-on internal switch (7 min.)

64-PV2100 and 64-PV2300 have 10.55mm dia. shaft and the 64-PV2618 and 64-PV2636 have a 5.8mm dia. shaft.

# 2-IN-1 DUAL SHAFT

Convertible borescope

## Now with 7400 pixels!



PV2-in-1 Series	Series Scope, Mirror, Magnet, Bulb & Hard Case
64-PV2618-21	18" Dual-Shaft/Convertible "2-in-1"
64-PV2636-21	36" Dual-Shaft/Convertible "2-in-1"

## 1 scope – 2 configurations!



Attaches Easily!

The 2-in-1 scope system features the flexible, thin ability of our 5.8mm shaft along with an additional "obedient" shaft that can be added easily to give you 2 scopes in 1 package.


# PROVISION ELITE

## SUPER HI RES

2-way articulated scope

Elite	2 Way Articulated Scope
64-PVAE624	24" 10,000 Pixels w/ Articulating Tip
No accessories available at this time	

A moving tip makes all the difference when looking for problems! This scope features a super high resolution view with over 10,000 pixels featuring a controllable 2-way articulating lens. The ergonomic articulating control knob turns the scope right or left, as little or as much as you need. Turn it on its side to look up or down.

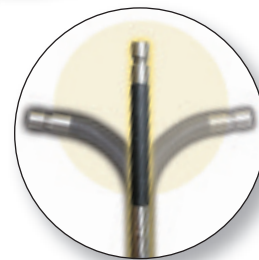

Articulating Tip

**NTE**  
ELECTRONICS, INC.

# ProVision®

THE ULTIMATE INSPECTION TOOL




**High Intensity  
Halogen Bulb**



**Clip On  
Magnetic Tip**



**Clip On  
Mirror for 45° Viewing**

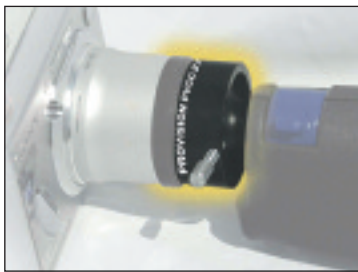

### Camera Coupler

This 37mm coupler will let most digital cameras and video cameras attach directly to the ProVision tools.

This item may require a step-up or step-down ring that is available at most camera shops.



### Rubber Eye Cup

See it clearer with the ProVision Eye Cup. Eliminate all external light on the viewing lens with this great eye cup.



### Protective Boots

Dress up your ProVision with these tough protective boots. We offer two styles in a variety of colors.

## Accessories & Attachments

### For PV1 Series

64-PVW45	45 deg. Mirror 10.5mm
64-PVW45M	45 deg. Mirror 5.8mm
64-PM1	Magnet 10.5mm
64-PM1M	Magnet 5.8mm
64-PL1000	High Intensity Halogen Bulb
64-PVKM45	Bulb, Mirror, Magnet Kit 10.5mm
64-PVKM45M	Bulb, Mirror, Magnet Kit 5.8mm
64-PVKWM	Mirror, Magnet Kit for PV300E
64-PVH36V	6V Lithium Battery Pack for PV300E
64-PVBBKG	Black Boot Gloss
64-PVBBKT	Black Boot Textured
64-PVBBUT	Blue Boot Textured
64-PVBRDT	Red Boot Textured
64-PVBYLG	Yellow Boot Gloss
64-PVBBKT-E	Black Boot Textured Elite Eagle PV1

### For PV2 Series

64-PL21000	High Intensity Halogen Bulb for PV2 Series
64-PV2K6BMW	Bulb, Mirror, Magnet Kit for PV2 Series Non-Obedient
64-PV2K11BMW	Bulb, Mirror, Magnet Kit for PV2 Series Obedient
64-PV2K6BW	Bulb, Mirror Kit for PV2 Series Non-Obedient
64-PV2K11BW	Bulb & Mirror Kit for PV2 Series Obedient
64-PV2M6	Magnet Kit for PV2 Series Non-Obedient
64-PV2M11	Magnet Kit for PV2 Series Obedient
64-PV2W6	Mirror Kit for PV2 Series Non-Obedient
64-PV2W11	Mirror Kit for PV2 Series Obedient

### PV1 & PV2 Series

64-PVCC37	37mm Camera Coupler
64-PVEG1	Eye Guard

### Literature

EL64-01	ProVision Brochure
---------	--------------------



Made in the USA

**NTE®**  
ELECTRONICS, INC.

NTE Electronics, Inc.  
44 Farrand Street,  
Bloomfield, NJ 07003-2597

For more information,  
visit [www.nteinc.com](http://www.nteinc.com)

Distributed By: